


UITVOERING GK/GK / BAUFORM GK/GK / MOUNTING STYLE GK/GK

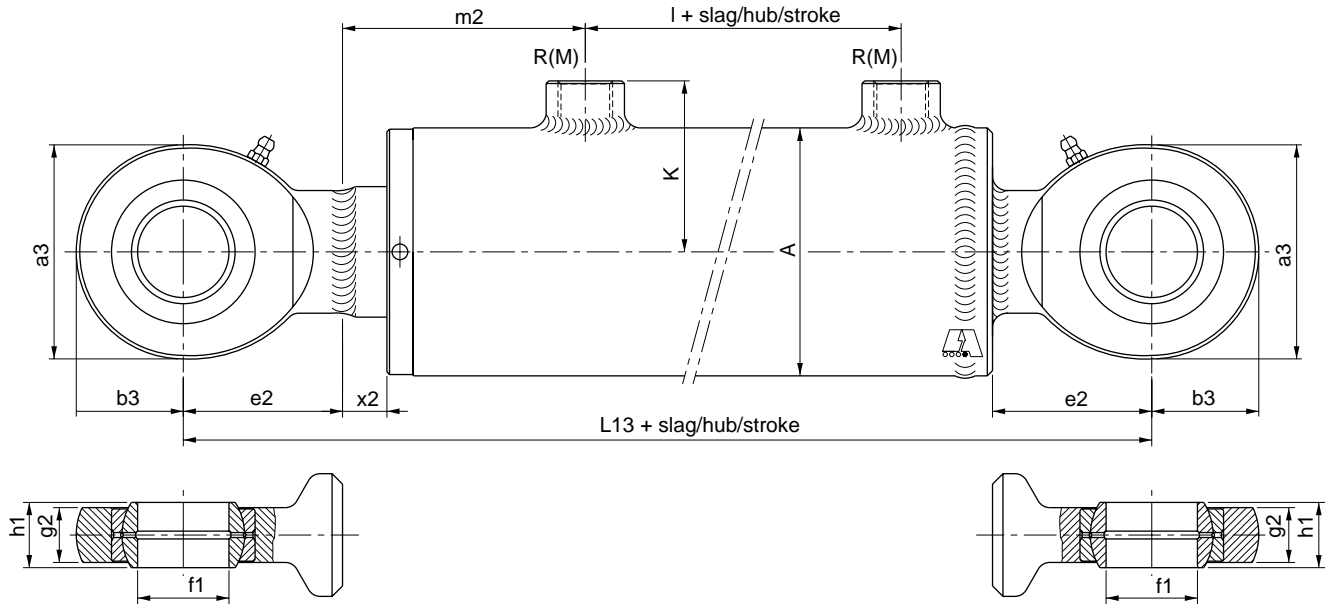

TYPE CILINDER		Afmetingen (mm)												
		R	L13	A	K	a3	b3	e2	f1	g2	h1	l	m2	x2
ACDGK/GK-	25/ 12	R1/8"	147	35	26	34	17	27	12	8	10	38	40	8
ACDGK/GK-	25/ 16	R1/8"	150	35	26	34	17	27	12	8	10	25	55	10
ACDGK/GK-	30/ 20 22	R1/4"	195	40	36	40	20	31	15	10	12	53	60	10
ACDGK/GK-	32/ 20 22	R1/4"	195	42	37	40	20	31	15	10	12	53	60	10
ACDGK/GK-	35/ 20 22 25	R1/4"	195	45	39	40	20	31	15	10	12	53	60	10
ACDGK/GK-	40/ 20 22 25 28 30	R3/8"	222	50	41	53	26,5	38	20	13	16	48	67	12
ACDGK/GK-	50/ 25 30 35	R3/8"	255	60	46	64	32	45	25	17	20	57	75	15
ACDGK/GK-	60/ 30 35 40	R1/2"	281	70	53	73	36,5	51	30	19	22	61	82	16
ACDGK/GK-	63/ 32 35 36 40 45	R1/2"	281	75	56	73	36,5	51	30	19	22	61	82	16
ACDGK/GK-	65/ 30 32 35 40 45	R1/2"	281	75	56	73	36,5	51	30	19	22	61	82	16
ACDGK/GK-	70/ 35 40 45 50	R1/2"	281	80	58	73	36,5	51	30	19	22	61	82	16
ACDGK/GK-	80/ 40 45 50 55 60	R1/2"	321	95	66	82	41	61	35	21	25	68	93	17
ACDGK/GK-	90/ 45 50 55 60 65	R1/2"	321	105	71	82	41	61	35	21	25	68	93	17
ACDGK/GK-	100/ 50 55 60 70	R1/2"	345	115	76	92	46	69	40	23	28	64	101	17
ACDGK/GK-	110/ 50 55 60 70	R1/2"	345	130	84	92	46	69	40	23	28	64	101	17
ACDGK/GK-	120/ 60 70 80 85	R3/4"	426	140	91	112	56	88	50	30	35	73	128	25
ACDGK/GK-	125/ 60 70 80 85 90	R3/4"	426	145	94	112	56	88	50	30	35	73	128	25
ACDGK/GK-	130/ 70 80 85	R3/4"	450	150	96	135	67,5	100	60	38	44	73	128	25
ACDGK/GK-	140/ 70 80 85 90 100	R3/4"	547	160	101	160	80	115	70	42	49	108	147	35
ACDGK/GK-	150/ 80 85 90 100	R3/4"	547	170	106	160	80	115	70	42	49	108	147	35
ACDGK/GK-	160/ 85 90 100 110	R1"	664	180	115	180	90	141	80	47	55	140	177	37