


# UITVOERING K/K / BAUFORM K/K / MOUNTING STYLE K/K

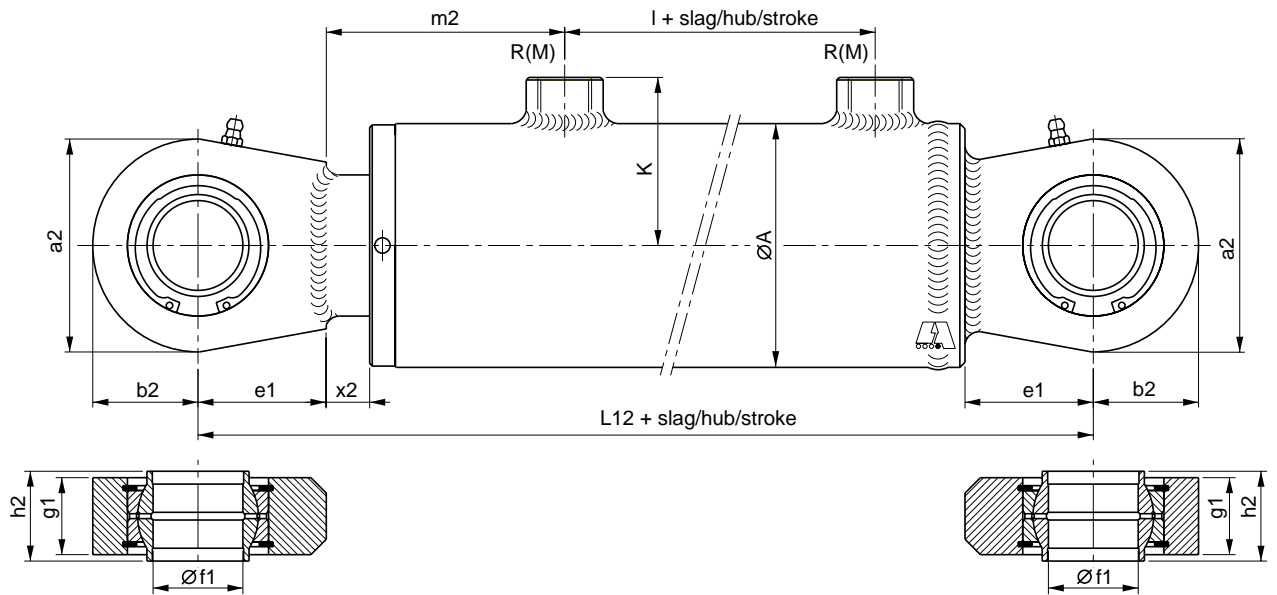

| TYPE CILINDER |           |           |     | Afmetingen (mm) |     |     |     |     |    |    |    |    |    |     |     |    |  |
|---------------|-----------|-----------|-----|-----------------|-----|-----|-----|-----|----|----|----|----|----|-----|-----|----|--|
|               |           |           |     | R               | L12 | A   | K   | a2  | b2 | e1 | f1 | g1 | h2 | l   | m2  | x2 |  |
| ACDK/K-40/    | 20<br>28  | 22<br>30  | 25  | R3/8"           | 206 | 50  | 41  | 50  | 25 | 30 | 20 | 19 | 24 | 48  | 67  | 12 |  |
| ACDK/K-50/    | 25        | 30        | 35  | R3/8"           | 235 | 60  | 46  | 55  | 28 | 35 | 25 | 23 | 29 | 57  | 75  | 15 |  |
| ACDK/K-60/    | 30        | 35        | 40  | R1/2"           | 259 | 70  | 53  | 65  | 33 | 40 | 30 | 28 | 30 | 61  | 82  | 16 |  |
| ACDK/K-63/    | 32<br>40  | 35<br>45  | 36  | R1/2"           | 259 | 75  | 56  | 65  | 33 | 40 | 30 | 28 | 30 | 61  | 82  | 16 |  |
| ACDK/K-65/    | 30<br>40  | 32<br>45  | 35  | R1/2"           | 259 | 75  | 56  | 65  | 33 | 40 | 30 | 28 | 30 | 61  | 82  | 16 |  |
| ACDK/K-70/    | 35<br>50  | 40        | 45  | R1/2"           | 259 | 80  | 58  | 65  | 33 | 40 | 30 | 28 | 30 | 61  | 82  | 16 |  |
| ACDK/K-80/    | 40<br>55  | 45<br>60  | 50  | R1/2"           | 299 | 95  | 66  | 83  | 41 | 50 | 35 | 30 | 35 | 68  | 93  | 17 |  |
| ACDK/K-90/    | 45<br>60  | 50<br>65  | 55  | R1/2"           | 299 | 105 | 71  | 83  | 41 | 50 | 35 | 30 | 35 | 68  | 93  | 17 |  |
| ACDK/K-100/   | 50<br>70  | 55        | 60  | R1/2"           | 327 | 115 | 76  | 100 | 50 | 60 | 40 | 35 | 38 | 64  | 101 | 17 |  |
| ACDK/K-110/   | 50<br>70  | 55        | 60  | R1/2"           | 327 | 130 | 84  | 100 | 50 | 60 | 40 | 35 | 38 | 64  | 101 | 17 |  |
| ACDK/K-120/   | 60<br>85  | 70        | 80  | R3/4"           | 390 | 140 | 91  | 123 | 61 | 70 | 50 | 40 | 43 | 73  | 128 | 25 |  |
| ACDK/K-125/   | 60<br>85  | 70<br>90  | 80  | R3/4"           | 390 | 145 | 94  | 123 | 61 | 70 | 50 | 40 | 43 | 73  | 128 | 25 |  |
| ACDK/K-130/   | 70        | 80        | 85  | R3/4"           | 390 | 150 | 96  | 140 | 70 | 70 | 60 | 50 | 54 | 73  | 128 | 25 |  |
| ACDK/K-140/   | 70<br>90  | 80<br>100 | 85  | R3/4"           | 467 | 160 | 101 | 164 | 82 | 75 | 70 | 55 | 65 | 108 | 147 | 35 |  |
| ACDK/K-150/   | 80<br>100 | 85        | 90  | R3/4"           | 467 | 170 | 106 | 164 | 82 | 75 | 70 | 55 | 65 | 108 | 147 | 35 |  |
| ACDK/K-160/   | 85<br>110 | 90        | 100 | R1"             | 572 | 180 | 115 | 180 | 90 | 95 | 80 | 60 | 74 | 140 | 177 | 37 |  |