

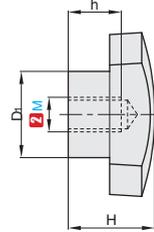




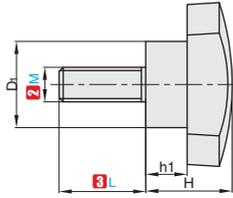


①代号	类型		M材质		表明处理
			握柄部颜色	螺纹部	螺纹部
TKCPWA	抗老化	外螺纹型	PA	SUM24L	镀锌
TKCPWB	防静电	外螺纹型	PF		
TKCPNA		内螺纹型		黄铜	-

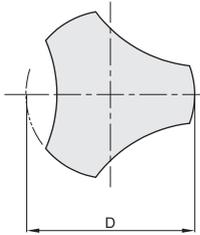


TKCPWB

TKCPNA(M5A/M6A/M8A/M10A)

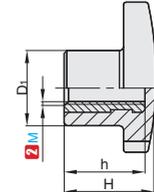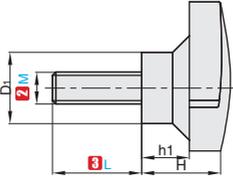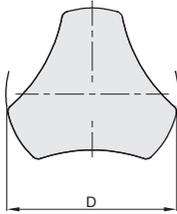

TKCPWA

 TKCPNA(M4/M5/M6/M8)



视角标准：第一视角

G1 手柄手轮(拉手)
合页/门组件



①代号 - ②M - ③L - ④握柄部颜色

TKCPNA - M5
TKCPWB - M6 - L10
TKCPNA - M6 - L20 - E

型号		③L	④握柄部颜色	D	D ₁	H	h ₁	参考重量 (kg/pcs)
①代号	②M							
TKCPWB	5	10	黑色	25	14	15	10	0.009
		20						
	6	10		31	17	17	11	0.015
		20						
		30						
8	20	39	20	20	12	0.027		
	30							
10	20	49	22	23	14	0.044		
	30							
	30							
TKCPWA	5	10	E(黑色) J(橘色)	29	11	15	7	0.01
		12						
	6	20						

型号		D	D ₁	H	h ₁	参考重量 (kg/pcs)
①代号	②M					
TKCPNA	4	16	10	10.5	6	0.007
	5	25	14	14	10	0.012
	5A		14	15	8.5	0.018
	6A	31	17	17	10	0.028
	6	32	17	19	12	0.01
	8A	39	20	20		
	8	40	22	21	16	
	10A	49	22	23	14	0.03



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

