

# 旋钮



## 六角旋钮




### ■ 六角旋钮



① 代号	类型	握柄部			螺纹部	
		M 材质	M 材质	S 表面处理	M 材质	S 表面处理
TKFPWA	六角旋钮	ABS	SS400	镀锌	外螺纹型	
TKFPWB					内螺纹型	
TKFPNA			黄铜			

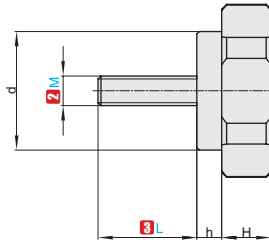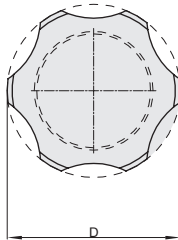

TKFPWA  
TKFPWB

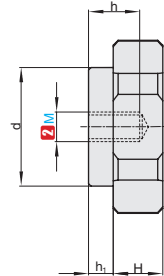

TKFPNA

#### 订购编号示例

① 代号	-	② M	-	③ L
TKFPWA	-	M6	-	L20
TKFPNA	-	M8	-	



型号		③ L	D	d	H	h	参考重量 (kg/pcs)
① 代号	② M						
TKFPWA	5	10 15 20 25 30	35	24	10	5	0.01
	6	10 15 20 25 30	42	26		7	0.02
	8	15 20 25 30 40 50	45	30		8	0.03
	10	30 40 50	50	33	11	9	0.05
TKFPWB	12	30 40 50	35	24	10	5	0.07
	6	20 30				7	0.02
	8	20 30 40	42	26		8	0.03
	10	30 40	45	30		9	0.04
TKFPNA	12	30 40 50	50	33	11	9	0.07

型号		D	d	H	h	h <sub>1</sub>	参考重量 (kg/pcs)
① 代号	② M						
TKFPNA	5	35	24	10	7	5	0.01
	6						0.01
	8	42	26		9	7	0.02
	10	45	30		10	8	0.02
	12	50	33		11	12	9



小单	中大单	大单
1-50	51-100	101-
通常	7工作日	现询



1-9	10~
100%	现询

G1  
门拉手  
手柄  
手轮  
合页