





①代号	类型		④材质	⑤表面处理
BKASBA	轻载型	扁嘴型	SUS304	滚磨抛光
BKASBD				震动抛光



安装孔孔距

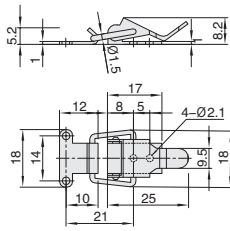


BKASBA
规格: 18

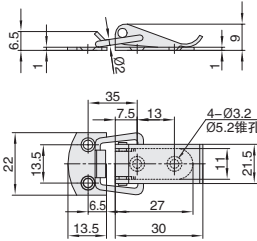


安装孔孔距




规格: 22

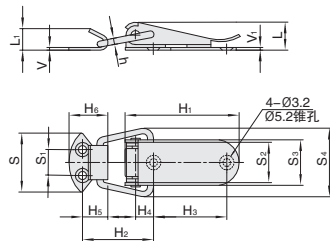

安装孔孔距

 


规格: 24/28

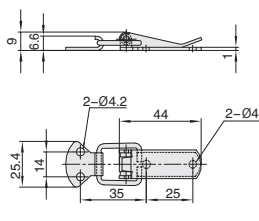


安装孔孔距




BKASBD
规格: 44

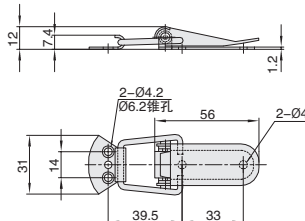


安装孔孔距

 


规格: 56

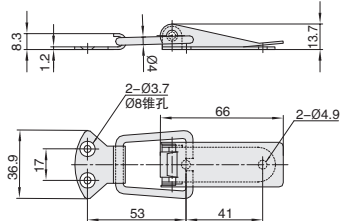

安装孔孔距

 


规格: 66

 

视角标准: 第一视角



①代号 - ②规格
BKASBA - 18

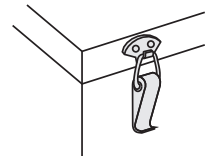

型号		拉伸承重 (kgf)	参考重量 (kg/pcs)
①代号	②规格		
BKASBA	18	5	0.01
	22	6	

型号		参考重量 (kg/pcs)
①代号	②规格	
BKASBD	44	
	56	0.06
	66	0.07

型号		H ₁	H ₂	H ₃	H ₄	H ₅	H _B	S	S ₁	S ₂	S ₃	S ₄	V	V ₁	h	L	L ₁	参考重量 (kg/pcs)
①代号	②规格																	
BKASBA	24	38	30	23	7	11	19	24	10	13	16	26	1.2	1	3	9.5	8	0.02
	28	53	33	34	8.5	11.5	18	28	12	15	21	32	1.5	1.5		13	9	0.04



数量分类	小单	中大单	大单
数量	1-50	51-100	100~
交货期	通常	7 工作日	现询



数量	1-9	10~
价格	100%	现询

G1 手柄
合页门组件
手柄
手
轮
拉
手