



拆卸式合页




代号	类型		拔插方向	材质	表面处理
HGCSVC	拔插型	圆孔型	左侧	SUS304	-
HGCSVD			右侧		

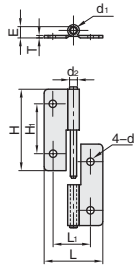


HGCSVC
规格: 52

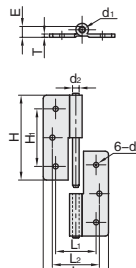


HGCSVC
规格: 65

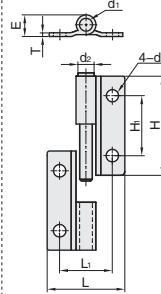

HGCSVD
规格: 52

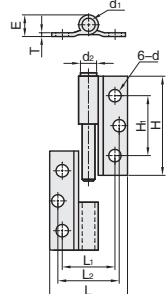

HGCSVD
规格: 65

 

视角标准：第一视角

G1
手柄/手轮/拉手
合页/门组件



①代号 - ②规格
HGCSVD - 52

代号	型号		L	H	L ₁	L ₂	H ₁	T	d	d ₁	E	负载 (kg)	参考重量 (kg/pcs)
	规格												
HGCSVC	52		37.5	52	27	-	30	1.6	6	5	8.5	6	0.04
HGCSVD	65		50	65	31	36	44	2.5	4	5	10.7	7	0.09



数量分类	小单	中大单	大单
数量	1~50	51~100	100~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	现询

