

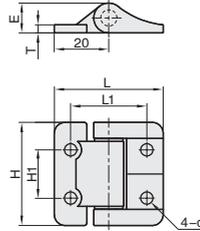
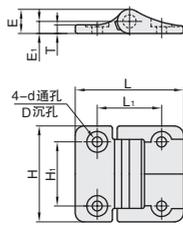
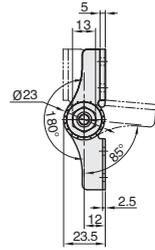


# 平型扭矩蝶形合页

 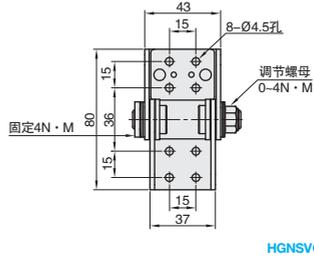


①代号	类型		调整角度	④材质	⑤表面处理/颜色
HGNSVB	阻尼型	圆孔型	任意角度定位型	SUS304	滚磨抛光
HGNSVC				SUS430	
HGNZYB				ZDC	

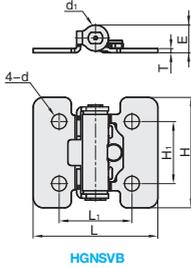

规格: 11/12/13

规格: 31/32/33/34/38



G1 手柄/门组件



①代号 - ②规格  
HGNSVB - 32

①代号	型号	L	H	L <sub>1</sub>	H <sub>1</sub>	T	d	E	d <sub>1</sub>	扭矩 N·M	参考重量 (kg/pcs)
HGNSVB	②规格 32	36	32	21	18	1.2	4.3	8	7.5	0.35	0.015
	40	48	40	32	26	2		9	8.5	0.7	0.03
	50		50		36			12.5	12	1.5	0.06

①代号	型号	L	H	L <sub>1</sub>	H <sub>1</sub>	T	d	D	E	E <sub>1</sub>	对称扭矩 N·M	负载 (kg)	参考重量 (kg/pcs)
HGNZYB	11										1.8		
	12	57	50.8	34	34	4.5	5.2	12	12.7	6.3	2.3	15	0.11
	13										3.4		
	31										2.8		
	32										1.4		
	33	40	38	28	17.8	3	4.5	-	11	-	1.8	10	0.04
	34										2.3		
38										0.9			

①代号	型号	扭矩 N·M	负载 (kg)	参考重量 (kg/pcs)
HGNSVC	80	4±20%~8	20	0.16



数量分类	小单	中大单	大单
数量	1~50	51~100	100~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	现询



爱安特自制模组, 火爆开售! 全零件备库, 最快 5 个工作日出货!



400-6699-428



www.ant-fa.com