






①代号	类型	性价比	④材质	⑤表面处理
HGPSJE	锥孔型	经济型	SUS304	镜面抛光
HGPSJD		普通型	SUS316	
HGPSJF		精密型		

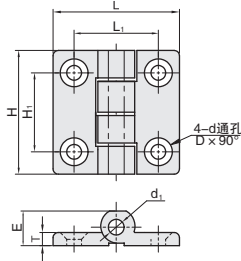


HGPSJD
规格:40/60

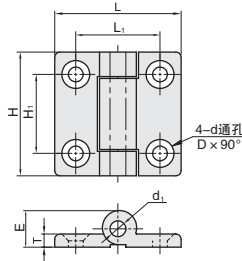


HGPSJD
规格:47/63/63A

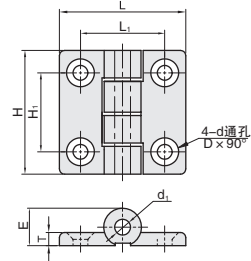


HGPSJD 规格:50/50A/65/75
HGPSJE 规格:50/65/75

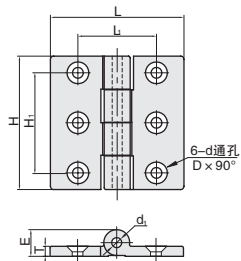


HGPSJD
HGPSJE
规格:100

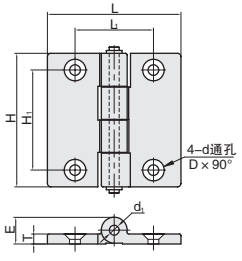

HGPSJF
规格:50/65/75

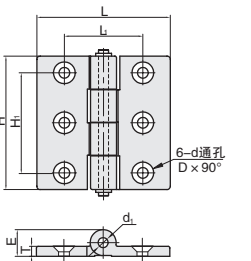

HGPSJF
规格:100

 

G1 手柄/门组件
手柄/门拉手



①代号 - ②规格
HGPSJD - 40

订购编号示例

型号		L	H	L ₁	H ₁	T	E	D	d	d ₁	负载 (kg)	参考重量 (kg/pcs)
①代号	②规格											
HGPSJD	40	40	40	25	25	5	9	10.4	5.2	4	30	0.11
	47	48	47	32	30	5	14	11	5.5		0.12	
	50	50	50	30	30	6	12	12.6	6.5	6	35	0.21
	50A			35	35							
	60	60	60	36	36	8	15	16.3	8.3	8	40	0.59
	63	62	63	42	37	5	14	13		6		0.06
	63A	80	63	47	43		16			8	45	0.11
	65	65	65	40	35		14			6	0.1	
	75	75	75	50	40		15			7	65	0.19
	100	100	100	60	60	6	16		6.5	8	85	0.19
HGPSJE HGPSJF	50	50	50	30	30			12	12.6		6	35
	65	65	65	40	35		14			6	45	0.21
	75	75	75	50	40		15			7	65	0.29
	100	100	100	60	60		16			8	85	0.52



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	现询

