

 


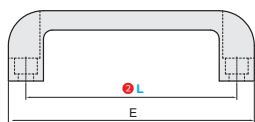



①代号	④材质	⑤表面处理/颜色
PHFPBA	ABS	橙色
PHFPBB		黑色
PHFNBA	PA6+GF30	-
PHFABA	ADC	喷塑(黑色)
PHFPBC	ABS	黑色
PHFPBD		橙色
PHFPBE		白色

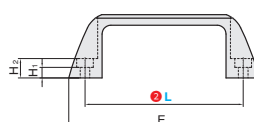



PHFPBA  
PHFPBB



 
PHFNBA

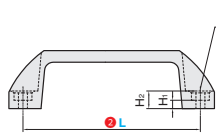

PHFABA

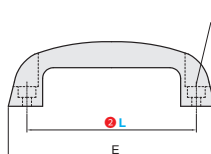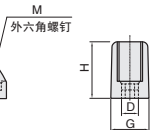

PHFPBD  
PHFPBE  
PHFPBC

 

视角标准：第一视角

G1 手柄/手轮/拉手  
合页/门组件



①代号 - ②L  
PHFPBA - L120

型号		E	D	D <sub>1</sub>	H	G	参考重量 (kg/pcs)
①代号	②L						
PHFPBA PHFPBB	120	140	8.8	13	40	24.5	0.04

型号		D	H	H <sub>1</sub>	H <sub>2</sub>	M	G	参考重量 (kg/pcs)
①代号	②L							
PHFABA	90	12	36	7	12	M6	20	0.12
	120	15	40	9	15	M8	26	0.14
	180		50		18		28	0.18

型号		E	D	D <sub>1</sub>	H	H <sub>1</sub>	G	参考重量 (kg/pcs)
①代号	②L							
PHFPBD	130	160	7	13	50	15	26	0.10
PHFPBE	150	180	8.7		55		27	0.12
PHFPBC	180	210					28	0.14



①代号 - ②L - ③H - ④拉手颜色  
PHFNBA - L90 - H36 - E

型号				H <sub>1</sub>	H <sub>2</sub>	E	G	参考重量 (kg/pcs)
①代号	②L	③H	④拉手颜色					
PHFNBA	90	36	E (黑色) W (白色) J (橙色) F (红色) L (绿色)	6	11	108.5	19	0.02
		51						0.03
	93.5	36		7	13	112	21	0.03
		51		9	15	139	26	0.04
	117	41		9	16	156	27	0.05
		57						0.6
	132	45		7	13	177	28	0.07
		63						0.09
	152	52		9	17	204		0.07
		50						0.09
179	71							



数量分类	小单	中大单	大单
数量	1-50	51-100	100~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询