


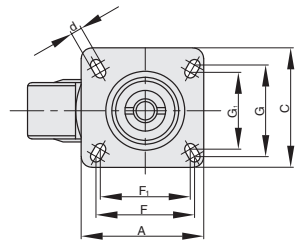
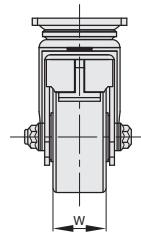
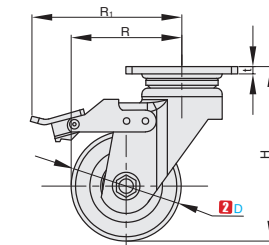


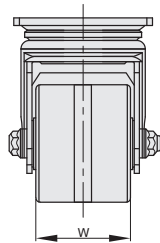

①代号	支架				轮部			
	类型	材质	表面处理	刹车形式	③材料代号	材质	颜色	轴承
HQ-CVBQXE	平底活动型	Q235A	喷涂(黑色)	-	UV	聚氨酯	自然色	双轴承
HQ-CVBBXA				尼龙单刹	NI	尼龙	黑色	

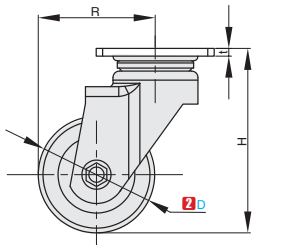

无刹
HQ-CVBQXE

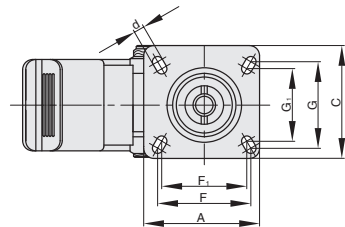

尼龙单刹
HQ-CVBBXA



视角标准：第一视角

▲ HQ-CVBQXE-D75-NS无UV材质。

G3
脚轮



①代号 - ②D - ③材料代号
HQ-CVBQXE - D75 - UV

型号		H	W	t	R	R ₁	A	C	F	F ₁	G	G ₁	d	容许载荷 (kg)			参考重量 (kg)			
①代号	②D	③材料代号												UV	NS	NI	UV	NS	NI	
无刹 HQ-CVBQXE	75	NS NI UV	115			68.5									-			-	1.70	1.70
	100	NS NI UV	157	48	6	100		100	100	78	64	78	64	10.5	400	600	600	2.40	2.30	2.30
尼龙单刹 HQ-CVBBXA	100	NS NI UV	157			100	136											2.50	2.40	2.40



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	另行报价

