 



①代号	③类型	支架				轮部			
		材质	表面处理	刹车形式	底板标准	③材料代号	材质	颜色	轴承
HQ-CVBQYM	平底活动型	Q235A	镀锌	-	欧式	UW	聚氨酯	深灰色	单滚珠轴承
HQ-CVBBY				五金双刹					



①代号 - ②D - ③材料代号
HQ-CVBQYM - D80 - UW

型号			H	W	R	R ₁	A	C	F	F ₁	G	G ₁	d	容许载荷 (kg)	容许载荷 (kg)	
①代号	②D	③材料代号													HQ-CVBQYM	HQ-CVBBY
无刹 HQ-CVBQYM 五金双刹 HQ-CVBBY	80	UW	102	32	78	115	100	85	80	76	60	55	9	150	0.60	0.70
	100		86		114	0.70									0.80	
	125		103		125	0.90									0.90	
	160		195	40	134	164	140	110	105	-	80	75	11	300	1.60	2.10

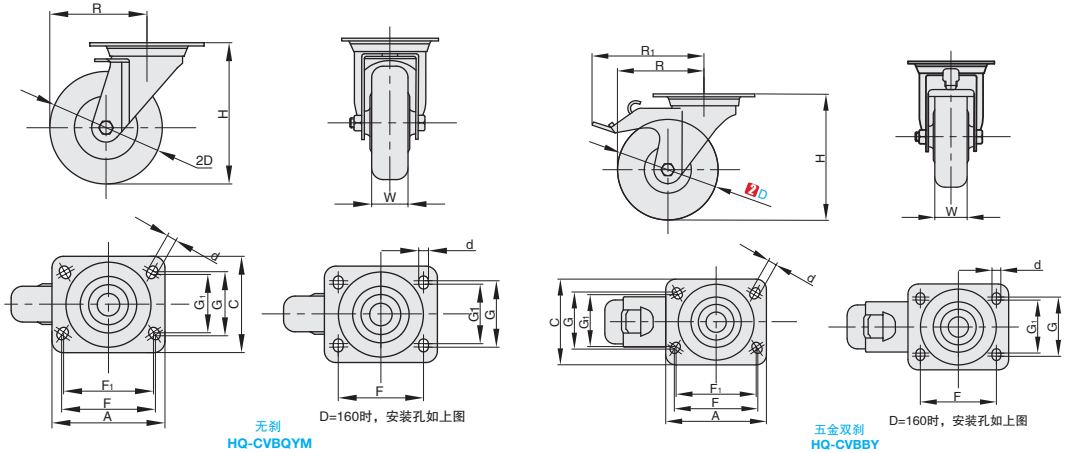

数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	另行报价

