



# 带壳磁铁

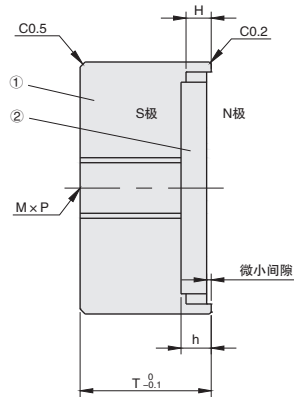

①代号	类型	①		②		最高工作温度
		M材质	S表面处理	M材质	S表面处理	
MTBVF	薄型	45#	无电解镀锌	钴磁铁	镀镍	80° C
MTBXF				钕磁铁		
MTBUNF		SUS416	-			
MTBUMF		45#	无电解镀锌	耐热钕磁铁		

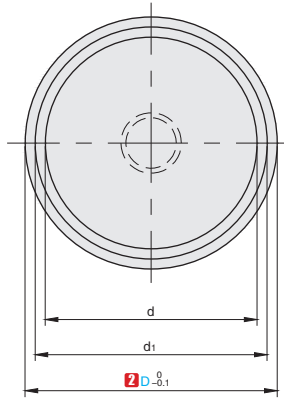

①代号 - ②D  
MTBVF - D4

①代号	②D	T	M×P	d	d <sub>1</sub>	h	H	吸附力(kgf)		表面磁通密度高斯(G)	
								MTBVF	MTBXF·MTBUNF·MTBUMF	MTBVF	MTBXF·MTBUNF·MTBUMF
(钴磁铁) MTBVF	4	4	2×0.4	2.5	3	1	0.5	-	0.06	-	2000~2400
	5			3.5	4			-	0.13	-	2000~2500
(钕磁铁) MTBXF	6	6	3×0.5	4	5	2	1.5	0.3	0.4	1900~2600	3000~3400
	8			5	6			0.4	0.7	2000~2600	2900~3300
(钕磁铁) MTBUNF	10	8	4×0.7	7	8	1.5	1	1	2	1900~2300	1900~2500
	13			9.5	11			3	4.5	2000~2400	2400~2700
(耐热钕磁铁) MTBUMF	16	10	5×0.8	12.5	14	2	1.5	5	9	2000~2500	2200~2600
	20			16.5	18			9	13	2100~2600	2500~2900
	25	13	6×1.0	21	23	3	2.5	13	20	2100~2600	2400~2800

▲ T=4时, MTBVF不可选。  
吸附力、表面磁通密度为参考值。