
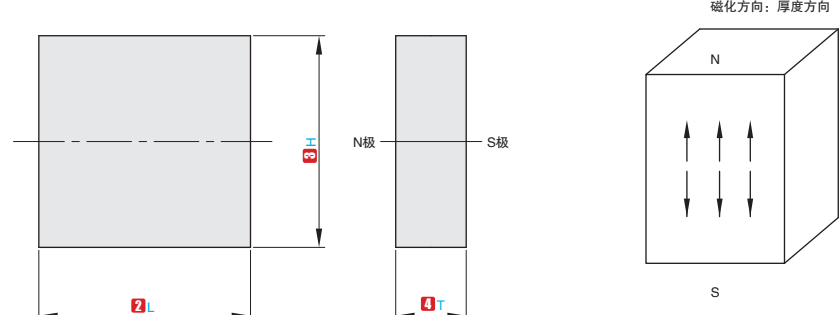


# 方形磁铁





①代号	类型	Ⓜ材质	耐热温度	Ⓢ表面处理
MTUY	方形磁铁	钕磁铁	80° C	镀镍



视角标准：第一视角

▲ 吸附力、表面磁通密度为参考值。



①代号 - ②L - ③H - ④T  
 MTUY - L3 - H3 - T5

①代号	②L	③H	④T	吸附力(kgf)	表面磁通密度高斯(G)
MTUY	3	3	5	0.29	3900~4300
	4	4	5	0.57	4100~4500
	5	5	5	0.91	4200~4600
	6	6	6	1.4	4300~4700
	8	8	6	2.37	4200~4600
			1	0.28	1500~1900
			2	0.87	2800~3200
	10		5	1.71	4000~4400
			1	0.66	1600~2000
		10	2	1.2	2300~2700
			8	4.01	4300~4700
			3	1.42	2900~3300
			5	2.42	3900~4300
	15		10	3.2	4500~4900
			3	2.44	2700~3100
			10	3.5	3100~3700
			10	6.27	4400~4800
	20		5	4.16	4400~4800
		10	4.87	3300~3700	
	10	5	7.94	4500~4900	
		15	7.11	3100~3700	
30		20	8.65	2900~3300	
		30	11.31	3100~3700	

K2  
磁铁

