


# 橡胶减震器

★ 产品特点: 具有良好的抗疲劳和耐久度。安装简便, 规格齐全。

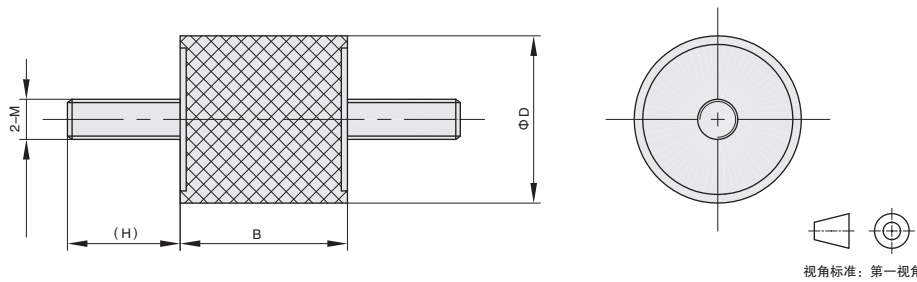

①代号	类型	④材质		橡胶⑤硬度(肖氏A)	⑥表面处理
		主体	金属零件		
RSBTD	两端外螺纹圆柱形	天然橡胶	钢	60±5HS	镀锌



J5 减震防护零件



①代号 - ②规格 - ③M  
RSBTD - 0808 - M3

①代号	②规格	③M	D	B	(H)	承载重量(kg)	最佳压缩量(mm)
RSBTD	0808	3	8	8	6	8	1.5
	1010	4	10	10	10	10	2
	1510	4	15	10	10	18	2
	1510	5	15	10	10	18	2
	1515	4	15	15	10	18	2
	1520	4	15	20	10	18	2
	2015	6	20	15	16	25	2
	2020	6	20	20	16	25	2
	2030	6	20	30	16	25	2
	2520	6	25	20	15	33	2
	2525	6	25	25	15	33	2
	3015	8	30	15	20	40	2
	3020	8	30	20	20	40	2
	3025	8	30	25	20	40	2
	3030	8	30	30	20	50	2.5
	4020	8	40	20	23	48	2
	4030	8	40	30	23	60	2.5
	4040	8	40	40	23	72	3
	5020	10	50	20	27	56	2
	5030	10	50	30	27	70	2.5
5040	10	50	40	27	85	3	
5050	10	50	50	27	85	3	
6030	12	60	30	37	110	2.5	
6040	12	60	40	37	110	2.5	
6060	12	60	60	37	132	3	