



按图定制

①代号	类型	M材质		⑤表面处理
		芯材	轴承	
VESN	轴承型	碳钢	钢	无电解镀锌
VEAY		铝合金	钢	本色阳极氧化处理

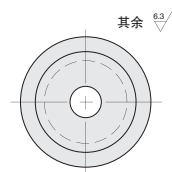

视角标准：第一视角

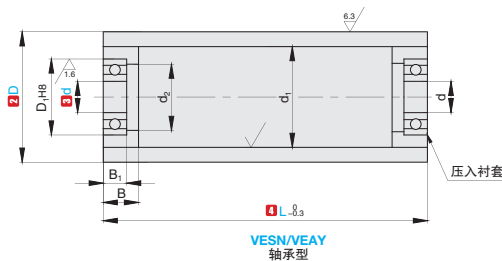

①代号 - ②D - ③d - ④L
 VESN - D40 - d15 - L200

型式		④d	⑤L	D ₁	B ₁	B	d ₁		d ₂		适用轴承	
①代号	②D						碳钢	铝合金	钢	铝合金		
VESN VEAY	40	8	550	24	8	12	22.7	22	15	15	RM628-2Z	
		10	600	26	8	12	22.7	22	15	15	R6000-2Z	
	50	10	650	30	9	15	40	27	17	17	R6200-2Z	
		12	700	28	8	15	40	27	22	22	R6001-2Z	
	60	12	800	32	10	15	49.5	32	22	22	R6201-2Z	
		15	850	32	9	15	49.5	32	22	22	R6002-2Z	
	80	25	900	52	15	20	68.6	41	41	38	R6205-2Z	
		30	950	55	13	20	68.6	41	41	38	R6006-2Z	
			1000									

▲轴承可拆卸。

M材质	D	规格有无	
		L550-L800	L850-L1000
碳钢	40		-
	50		
	60		
	80		
铝合金	40		-
	50		
	60		
	80		