


 


①代号	类型	套筒材质
ZYSX	弹簧压入式	钢制镀锌
ZYSS		不锈钢304
ZYA		铝合金

▲特点:适用于中、重负载输送,运行良好,适用性好。

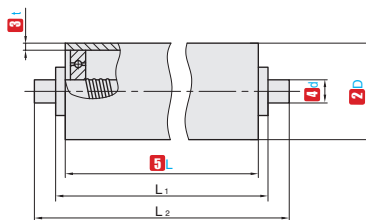

ZYSX/ZYSS/ZYA
弹簧压入式



视角标准:第一视角



①代号	-	②D	-	③t	-	④d	-	⑤L
ZYSX	-	D38	-	t1.2	-	d12	-	L500

型号		③t	④d		⑤L	L ₁	L ₂
①代号	②D						
ZYSX ZYSS ZYA	■38	1.2	12		200~1800	L+9	L+31
	▲38.2	1.5	12				
	▲■50	1.5	12	15	200~1900	L+10	L+32
	■50	2	12				
	▲■60	2	12	15	200~1900	L+10	L+32
	■60	3		15			
	■76	3		20		L+9	L+31
	▲76	3		15			
	■76	3		20	200~1900	L+10	L+40
	▲76	3		15			
	■76	4		20			
	■80	3		20			
■89	3		20				

▲使用温度: 尺寸为直径D=80,壁厚t=4和直径D=38.2,壁厚t=1.5只有铝合金材质

▲铝合金仅有标注▲的尺寸

▲不锈钢仅有标注■的尺寸

▲使用温度: -20°C ~80°C

