

精致型高扭矩橡胶带

S2M 型



■ S2M 型

进口产品

CAD 2D/3D



RoHS

标准加工袋


型式	齿面保护层	材质	芯线
HQ-ABRN-S2M	尼龙帆布	氯丁橡胶	玻璃纤维

产品特点：应用于通讯食品机械、医疗机械、钢铁机械、石油化工、仪器仪表、各种精密机床等。

▲使用温度 -20~80°C。

订购编号示例

① 代号	-	② 齿形	③ 公称宽度	-	④ 编号
HQ-ABRN	-	S2M	040	-	84

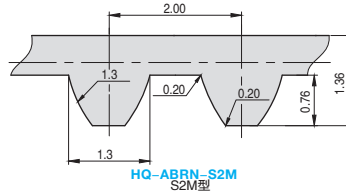

HQ-ABRN-S2M (齿距: 2mm)						HQ-ABRN-S2M (齿距: 2mm)						HQ-ABRN-S2M (齿距: 2mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数	① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数	① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
HQ-ABRN	S2M	040 (4mm)	84	84	42	HQ-ABRN	S2M	040 (4mm)	202	202	101	HQ-ABRN	S2M	040 (4mm)	360	360	180
			90	90	45				204	204	102				376	376	188
			92	92	46				206	206	103				380	380	190
			98	98	49				210	210	105				386	386	193
			100	100	50				212	212	106				396	396	198
			102	102	51				214	214	107				400	400	200
			104	104	52				218	218	109				426	426	213
			106	106	53				220	220	110				438	438	219
			110	110	55				224	224	112				442	442	221
			112	112	56				230	230	115				444	444	222
		116	116	58	236	236	118	448	448	224							
		118	118	59	240	240	120	452	452	226							
		120	120	60	244	244	122	460	460	230							
		122	122	61	246	246	123	474	474	237							
		124	124	62	248	248	124	494	494	247							
		128	128	64	250	250	125	520	520	260							
		130	130	65	252	252	126	530	530	265							
		132	132	66	256	256	128	560	560	280							
		134	134	67	258	258	129	600	600	300							
		140	140	70	260	260	130	604	604	302							
142	142	71	262	262	131	648	648	324									
144	144	72	264	264	132	710	710	355									
146	146	73	266	266	133	800	800	400									
148	148	74	274	274	137	930	930	465									
150	150	75	276	276	138												
152	152	76	278	278	139												
156	156	78	280	280	140												
158	158	79	286	286	143												
160	160	80	288	288	144												
164	164	82	290	290	145												
166	166	83	300	300	150												
168	168	84	304	304	152												
172	172	86	308	308	154												
174	174	87	312	312	156												
176	176	88	316	316	158												
178	178	89	318	318	159												
180	180	90	320	320	160												
182	182	91	324	324	162												
186	186	93	328	328	164												
190	190	95	334	334	167												
192	192	96	344	344	172												
196	196	98	350	350	175												
200	200	100	354	354	177												

G5
手柄/手轮
门组件
合页