

精致型高扭矩橡胶带

S5M 型



■ S5M 型

进口产品

CAD 2D/3D




标准加工

型式	齿面保护层	材质	芯线
HQ-ABRN-S5M	尼龙帆布	氯丁橡胶	玻璃纤维

产品特点: 用于通讯食品机械、医疗机械、钢铁机械、石油化工、仪器仪表、各种精密机床等。

▲ 使用温度 -20~80°C。

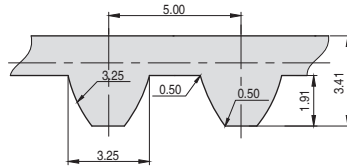

订购编号示例

① 代号	-	② 齿形	③ 公称宽度	-	④ 编号
HQ-ABRN	-	S5M	100	-	230

HQ-ABRN-S5M
S5M 型

HQ-ABRN-S5M (齿距: 5mm)						HQ-ABRN-S5M (齿距: 5mm)						HQ-ABRN-S5M (齿距: 5mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数	① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数	① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
HQ-ABRN	S5M	100 (10mm)	230	230	46	HQ-ABRN	S5M	100 (10mm)	700	700	140	HQ-ABRN	S5M	100 (10mm)	1595	1595	319
			255	255	51				710	710	142				1605	1605	321
			260	260	52				720	720	144				1680	1680	336
			295	295	59				725	725	145				1690	1690	338
			300	300	60				730	730	146				1715	1715	343
			305	305	61				740	740	148				1800	1800	360
			320	320	64				750	750	150			2000	2000	400	
			325	325	65				765	765	153			2145	2145	429	
			340	340	68				780	780	156			2480	2480	496	
			350	350	70				800	800	160						
			360	360	72				810	810	162						
			375	375	75				830	830	166						
		380	380	76	845			845	169								
		390	390	78	850			850	170								
		395	395	79	870			870	174								
		400	400	80	890			890	178								
		415	415	83	900			900	180								
		425	425	85	930			930	186								
		435	435	87	950			950	190								
		440	440	88	965			965	193								
		450	450	90	975			975	195								
		475	475	95	980			980	196								
		490	490	98	1000			1000	200								
		500	500	100	1025			1025	205								
		520	520	104	1050			1050	210								
		525	525	105	1085			1085	217								
		530	530	106	1090			1090	218								
		545	545	109	1100			1100	220								
		550	550	110	1115			1115	223								
		560	560	112	1125			1125	225								
		575	575	115	1145			1145	229								
		590	590	118	1160			1160	232								
		595	595	119	1165			1165	233								
		600	600	120	1195			1195	239								
		615	615	123	1225			1225	245								
		625	625	125	1250			1250	250								
640	640	128	1270	1270	254												
650	650	130	1290	1290	258												
665	665	133	1295	1295	259												
670	670	134	1350	1350	270												
675	675	135	1420	1420	284												
690	690	138	1500	1500	300												
695	695	139	1530	1530	306												

G5
手柄/手轮
门组件