 







CAD 2D 3D



标准加工  
按图定制

代号		类型	M材质			S表面处理		
同步带宽: 10mm	同步带宽: 15mm		带轮	法兰	衬套	带轮	法兰	衬套
APZAA-AT5100	APZAA-AT5150	标准型 沉孔型	铝合金	铝合金	45#	本色阳极氧化	本色阳极氧化	四氧化三铁保护膜

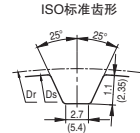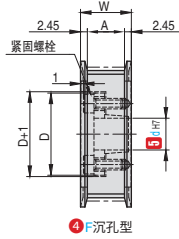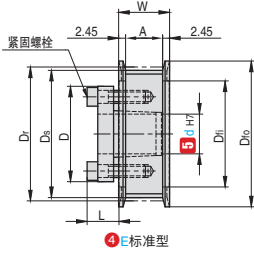

△齿槽尺寸会因齿数不同而略有差异  
括号内尺寸为AT10型  
(AT5间距:5mm AT10间距:10mm)



1 代号 - 2 公称宽度 - 3 齿数 - 4 带轮形状 - 5 轴孔径  
APZAA - AT5100 - 30 - E - d12

代号			4 带轮形状	5 d (轴孔按 1mm 为单位指定或选择)				Dr	Ds	Dfo	Dfi
1 代号	2 公称宽度	3 齿数		AT5100		AT5150					
				E型 (ST衬套)	F型 (ST衬套)	E型 (ST衬套)	F型 (ST衬套)				
APZAA	AT5100 A: 11.6 W: 16.5	22		8	-	-	-	35.01	33.85	40	27
		24		8~10		10	8	38.2	37	45	30
		25			8			39.79	38.6		
		26		8~12		10~12	8~10	41.38	40.2	48	35
	AT5150 A: 16.6 W: 21.5	28					8~11	44.56	43.35		
		30		10~15		10~15		47.75	46.55	52	36
		32						50.93	49.7	55	40
		36		10~17		10~17	10~12	57.3	56.05	61	45
		40					63.66	62.45	67	50	

△ 轴孔内有可能未进行表面处理;  
⊗ ST衬套以下规格不能制作: 9; 13;  
⊗ SH衬套以下规格不能制作: 9; 13;

尺寸参考

△ 衬套规格表见 P942  
△ 追加工详情页见 P944



百万商品齐上线, 获取专属企业折扣, 轻松下单



400-6699-428



www.ant-fa.com