

铜合金带肩标准型 / 薄壁型

内径 E7 外径 r6



大批量
订购
bulk order

库存产品



■内径 E7 外径 r6



代号	类型	材质	内径公差	外径公差	硬度 HB	使用温度范围 (°C)
OFAFZ	带肩标准型	高力黄铜 + 固体润滑剂 GR1	E7	r6	≥210	-50~150
OFAFZU	带肩薄壁型	高力黄铜 + 固体润滑剂 GR1	E7	r6	≥210	-50~150

产品特点: 可防止从板材上脱落的带肩规格。

▲配套轴 (大气、油中使用) 公差推荐 (仅供参考):
d8: 一般用 (重载); e7: 一般用 (轻载);
f8: 高精度用; g6: 高精度用 (间隙负载)
▲底座孔推荐公差: H7

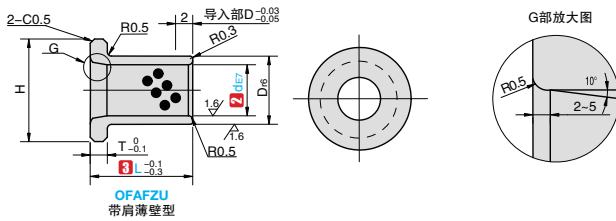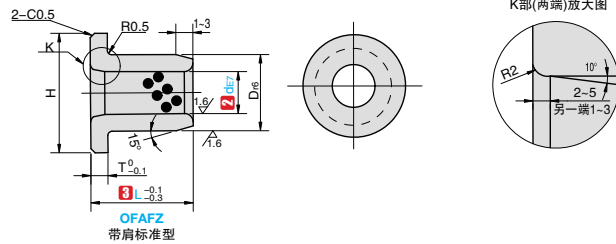

订购编号示例

1 代号	-	2 d	-	3 L
OFAFZU	-	d20	-	L20

型号		D _{r6}		3 L							H	底座孔 推荐公差	T		
1 代号	2 d _{E7}														
OFAFZ	5	+0.032	9	+0.028	10	12	15					14	+0.015 0	2	
	6	+0.020	10	+0.019	10	12	15	20				16			
	8	+0.040	12	+0.034 +0.023	10	12	15	20	25			20	+0.018 0		
	10	+0.025	14		10	12	15	20	25	30	35	22			
	12		18		10	12	15	20	25	30	35	25	+0.021 0	3	
	13	+0.050	19		10	12	15	20	25	30	35	26			
	15	+0.032	21	+0.041 +0.028	10	12	15	20	25	30	35	28	+0.021 0		
	16		22		12	15	20	25	30	35	40	50			29
	18		24			15	20	25	30	35	40	50	32	+0.025 0	5
	20		30			15	20	25	30	35	40	50	40		
25	+0.061	35	+0.050 +0.034		15	20	25	30	35	40	50	60	45	+0.025 0	
30	+0.040	40		20	25	30	35	40	50	60	50				
35		45			20	25	30	35	40	50	60	60	+0.030 0		
40	+0.075	50			20	25	30	35	40	50	60	65			
50	+0.050	60	+0.060 +0.041					30	35	40	50	60	75		

型号		D _{r6}		3 L							H	底座孔 推荐公差	T	
1 代号	2 d _{E7}													
OFAFZU	5	+0.032	7	+0.028	10	12	15					11	+0.015 0	2
	6	+0.020	8	+0.019	10	12	15	20				12		
	8	+0.040	10	+0.034 +0.023	10	12	15	20				14	+0.018 0	
	10	+0.025	12		10	12	15	20	25	30	16			
	12		15		10	12	15	20	25	30	21	+0.021 0	3	
	13	+0.050	16			12	15	20	25	30	22			
	15	+0.032	18	+0.041 +0.028	10	12	15	20	25	30	24	+0.021 0		
	16		20			12	15	20	25	30	40			26
	20		24			15	20	25	30	40	50	32	+0.025 0	4
	25	+0.061	29			20	25	30	40	50	37			
30	+0.040	34	+0.050 +0.034					25	30	40	50	42		



交货期
5 工作日



优惠价
1-9 100%
10- 现询

B2
无油衬套