

双列交叉滚子导轨


大批量
订购
bulk order

NEW
新产品

CAD
2D/3D



代码	类型	导轨		保持架	滚柱
		材质	表面处理	材质	材质
CRD	双列交叉滚子导轨	SUJ2	-	SUS304	SUJ2

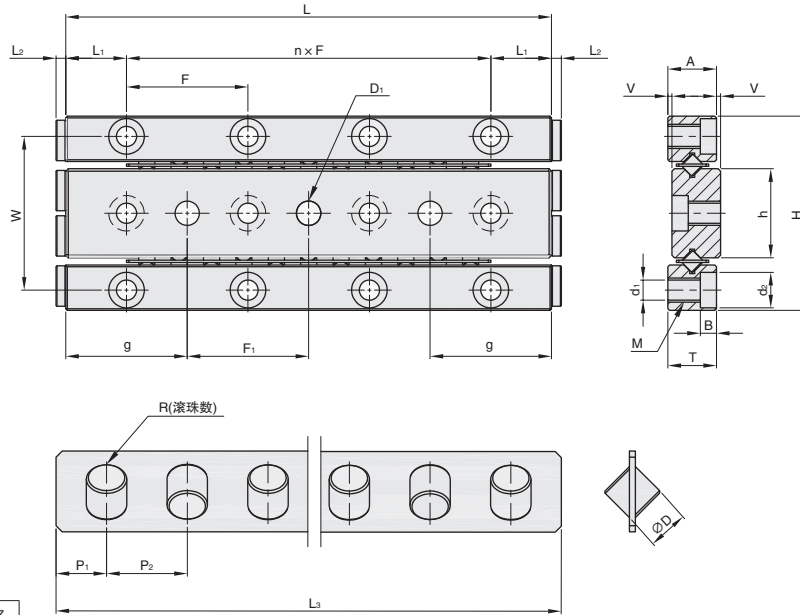

订购编号示例

①代号 - ②规格
CRD - 1030

型号		外形尺寸							保持器规则					安装孔尺寸							基本额定负荷					
①代号	②规格	最大行程	H	T	L	A	h	V	D	L ₃	R	P ₁	P ₂	W	L ₁	L ₂	n×F	g	F ₁	D ₁	M	d ₁	d ₂	B	C(动) N	Co(静) N
CRD	1020	12	17	4.5	20	4	7.8	0.5	1.5	14	5	2	2.5	13.4	5	1.5	1×10	10	10	2	M2	1.65	3	1.4	345	880
	1030	22			30					19	7						2×10								483	1408
	2030	18			30					21	5						1×15								635	1936
	2045	24	24	6.5	45	6	11		2	33	8	2.5	4	19	7.5	2	2×15	15	15	3	M3	2.55	4.4	2	1016	2288
	2060	30			60					45	11						3×15								1397	2541
	2075	44			75					53	13						4×15								1651	3630
	3050	28	36	8.5	50	8	16.6		3	36	7	3	5	29	12.5	2.5	1×25	25	25	4	M4	3.3	6	3.1	1925	5082
	3075	48			75					51	10						2×25								2750	3630
	30100	58			100					71	14						3×25								3850	5082
	30125	78	44	11.5	125	11	20.4		4	86	17	4.5	7	35	20	2.5	4×25	40	40	5	M5	4.3	8	4.2	4675	6171
	30150	88			150					105	21						5×25								5775	7623
	4080	58			80					51	7						1×40								4459	5348
40120	82	120	79	11	2×40	7007	8404																			

⚠交叉滚子导轨耐冲击性弱，掉落或对其施力过大，会出现滑动异常，请小心注意。



1-9 10-
6 工作日 现询



1-9 10-
100% 另行报价

B3
直线导轨