

标准型

 

向心关节轴承



★ 产品特点: 载荷大, 抗冲击能力强, 抗腐蚀, 耐磨损调心, 润滑好, 即使安装错位也能正常工作



①代号	类型	外圈		内圈	
		材质	热处理	材质	热处理
BGEE	标准型	GCr15	淬火	GCr15	淬火
BGEES					

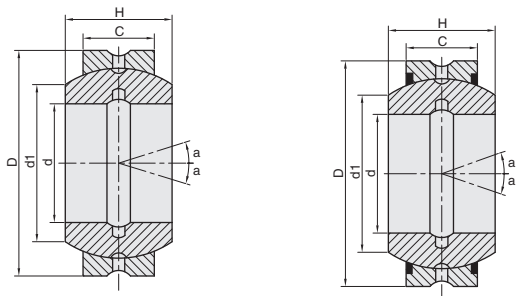

视角标准: 第一视角



型号
BGEE-45E

①代号	型号		d	D	H	C	d1 (min)	调整角	额定载荷		重量(g)
	②公称规格								动载荷/KN	静载荷/KN	
	5E	-	5	14	6	4	7	13	3.4	17	3.8
	6E	-	6	14	6	4	8	13	3.4	17	4.2
	8E	-	8	16	8	5	10	15	5.5	27	7.5
	10ES	-	10	19	9	6	13	12	8.1	40	11
	12ES	-	12	22	10	7	15	10	10	54	15
	15ES	15ES-2RS	15	26	12	9	18	8	17	85	27
	17E	17ES-2RS	17	30	14	10	20	10	21	106	41
	20E	20ES-2RS	20	35	16	12	24	9	30	146	66
	25E	25ES-2RS	25	42	20	16	29	7	48	240	119
	30E	30ES-2RS	30	47	22	18	34	6	62	310	153
	35E	35ES-2RS	35	55	25	20	39	6	80	400	233
	40E	40ES-2RS	40	62	28	22	45	7	100	500	306
	45E	45ES-2RS	45	68	32	25	50	7	127	640	427
	50E	50ES-2RS	50	75	35	28	55	6	156	780	546
	60E	60ES-2RS	60	90	44	36	66	6	245	1220	1040
	70E	70ES-2RS	70	105	49	40	77	6	315	1560	1550
	80E	80ES-2RS	80	120	55	45	88	5	400	2000	2310
	90E	90ES-2RS	90	130	60	50	98	5	490	2450	2750
	100E	100ES-2RS	100	150	70	55	109	7	610	3050	4450
	110E	110ES-2RS	110	160	70	55	120	6	655	3250	4820
	120E	120ES-2RS	120	180	85	70	130	6	950	4750	8050
	140E	140ES-2RS	140	210	90	70	150	7	1080	5400	11020
	160E	160ES-2RS	160	230	105	80	170	8	1370	6800	14010
	180E	180ES-2RS	180	260	105	80	192	6	1530	7650	18650
	200E	200ES-2RS	200	290	130	100	212	7	2120	10600	28000
	220E	220ES-2RS	220	320	135	100	238	8	2320	11600	35510
	240E	240ES-2RS	240	340	140	100	265	8	2550	12700	39910
	260E	260ES-2RS	260	370	150	110	285	7	3050	15300	51540

▲ 1kgf=9.8N

▲ 不承诺此产品品牌



交货期

4天发货



爱安特自制模组, 火爆开售! 全零件备库, 最快5个工作日出货!



400-6699-428



www.ant-fa.com