



ISO gerade Kabel-Schlauch-Verschraubung, Aussen- gewinde, Messing-vernickelt.

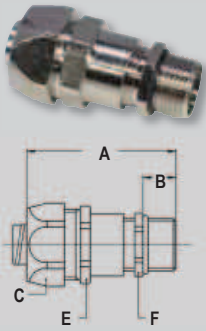


Gewinde	Sealtite	Klemm- bereich (mm)	Abmessungen in mm					Standard	Artikel	Gewicht
			A	B	C	E	F			
ISO M16 x 1,5	5/16"	4 - 8	57	12	26	24	18	25	812.715.2	6,0
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	25	812.716.1	7,8
M20 x 1,5	3/8"	6 - 10,2	57	12	26	24	22	25	812.717.1	9,5
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	25	812.720.1	9,7
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	25	812.722.1	11,7
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	25	812.728.1	20,2
M40 x 1,5	1"	18 - 23,8	83	15	45	43	43	10	812.735.1	32,6
M40 x 1,5	1.1/4"	22 - 31,8	96	15	54	52	43	5	812.740.1	46,0
M50 x 1,5	1.1/4"	22 - 31,8	96	15	54	52	55	5	812.745.1	60,0

ISO gerade EMV Kabel-Schlauch-Verschraubung, Aussen- gewinde, Messing-vernickelt.

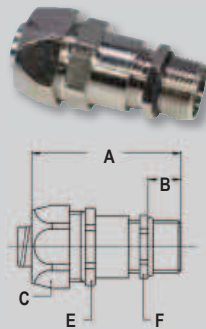

Gewinde	Sealtite	Klemm- bereich (mm)	Abmessungen in mm					Standard	Artikel	Gewicht
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 8	57	12	26	24	18	25	812.615.2	6,0
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	25	812.616.1	7,8
M20 x 1,5	3/8"	6 - 10,2	57	12	26	24	22	25	812.617.1	9,5
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	25	812.620.1	9,7
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	25	812.622.1	11,7
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	25	812.628.1	19,6
M40 x 1,5	1"	18 - 23,8	83	15	45	43	43	10	812.635.1	35,4


Pg gerade Verschraubung, Aussengewinde, Messing-vernickelt.

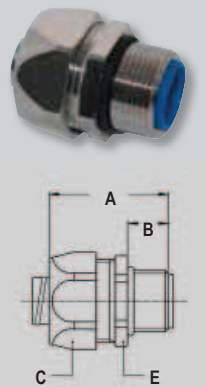

Gewinde	Sealtite	Min. Innen	Abmessungen in mm					Standard	Artikel	Gewicht
			Durchm. (mm)	A	B	C	D			
Pg 7	1/4"	5,2	33	10	22	-	20	50	810.007.1*	3,0
Pg 9	5/16"	8,3	35	12	26	-	24	50	810.009.1*	4,8
Pg 11	5/16"	8,3	35	12	26	-	24	50	810.012.1*	5,6
Pg 13,5	5/16"	8,3	35	12	26	-	24	50	810.014.1*	5,6
Pg 9	3/8"	10,2	35	12	26	-	24	50	810.010.1	4,8
Pg 11	3/8"	10,2	35	12	26	-	24	50	810.011.1	5,6
Pg 13,5	3/8"	10,2	35	12	26	-	24	50	810.013.1	5,6
Pg 16	1/2"	13,9	37	13	29	-	27	50	810.016.1	6,3
Pg 21	3/4"	18,5	40	15	35	-	33	25	810.021.1	8,4
Pg 29	1"	23,8	46	15	45	-	43	10	810.029.1	25,0
Pg 36	1.1/4"	31,8	52	16	54	-	52	5	810.036.1	34,6
Pg 42	1.1/2"	36,8	56	18	63	-	60	5	810.042.1	47,2
Pg 48	2"	47,8	66	20	77	-	74	4	810.048.1	72,0

* Verschraubungen für 1/4" und 5/16" Schlauch ohne UL/CSA Zulassung.

Pg gerade Verschraubung, kleine Ausführung, Aussen- gewinde, Messing-vernickelt

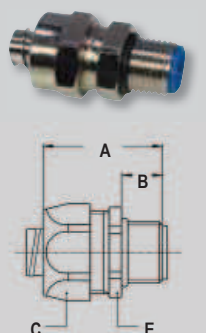

Gewinde	Sealtite	Min. Innen	Abmessungen in mm					Standard	Artikel	Gewicht
			Durchm. (mm)	A	B	C	D			
Pg 7	1/4"	5,2	33	10	19	-	17	50	810.007.2	2,8
Pg 9	5/16"	8,3	35	12	22	-	20	50	810.009.2	3,8

ANACONDA
VERSCHRAU-
BUNGEN

VERSCHRAU-
BUNGEN FÜR
SEALTITE
IP 67