



# CPH 850 V1


Heavy Load

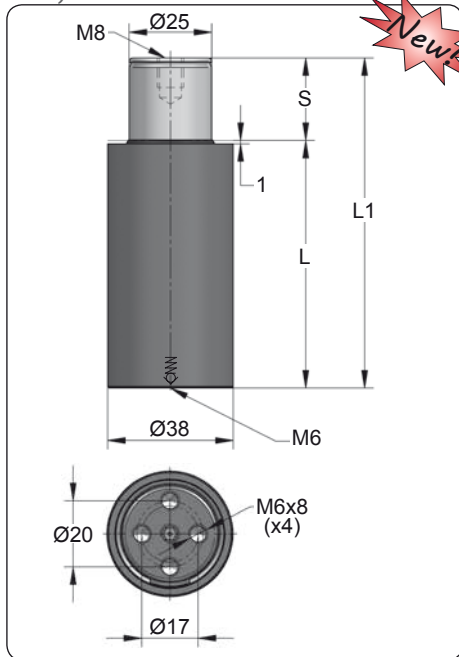


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CPH 850 012 V1	12	74	62	0,43
CPH 850 025 V1	25	100	75	0,50
CPH 850 038 V1	38	130	92	0,58
CPH 850 050 V1	50	155	105	0,64
CPH 850 063 V1	63	185	122	0,72
CPH 850 080 V1	80	225	145	0,82

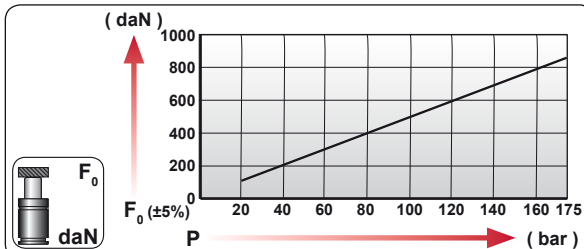

CODE					
		bar	psi		
CPH 850 050 V1		165	2395	810	1420
-----		---	---	---	---

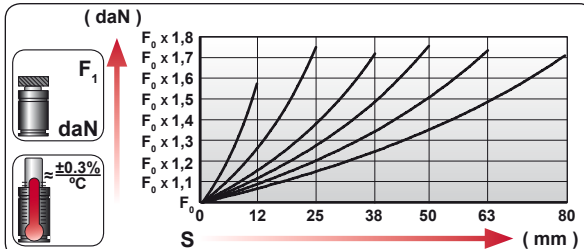

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO		
		daN	mm
		CPH 850	50
		CPH 850 050 V1	

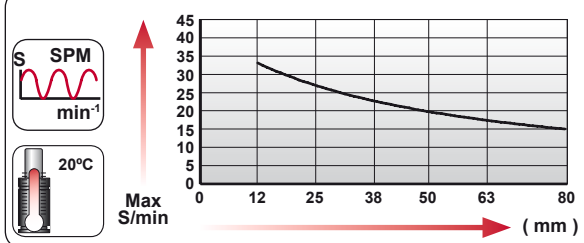

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub>	T <sub>max</sub>	






bar	psi	bar	psi	°C	°F	°C	°F	
20	290	175	2540	0	32	80	176	



# CPH 850 V1 MOUNTS

  Heavy Load

<p>s mm</p>	<p>mm</p>	<p>mm</p>	50	50	50	50	50	50	50
			Ø38	Ø38	Ø38	Ø38	Ø38	Ø38	Ø38
			L1=130 L1=140	L1=150	L1=132 L1=137	L1=150 L1=155	L1=150	L1=155 L1=160	L1=230
MODEL	<b>X</b>	CW 500 KZ 500	AS 300	CT 550 CK 570	CM 500 CD 500	APFA 250	<b>CPH 850</b> <b>CP 1000</b>	CS 1000	
SERIES	MINI	COMPACT HEIGHT	THREADED	LOW PROFILE	HEAVY DUTY	ISO	HEAVY LOAD	POWER COMPACT STROKE	

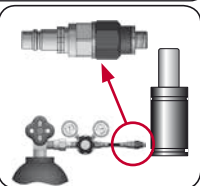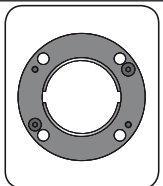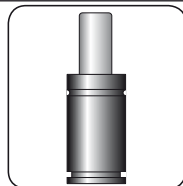

CODE	<b>CPH 850 050 V1</b>	<b>KIT S-XXXXXXX</b>	<b>X</b>	<b>06 CG 2-Q</b>
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA