


# CS-KC 11800 V1



Power Compact Stroke

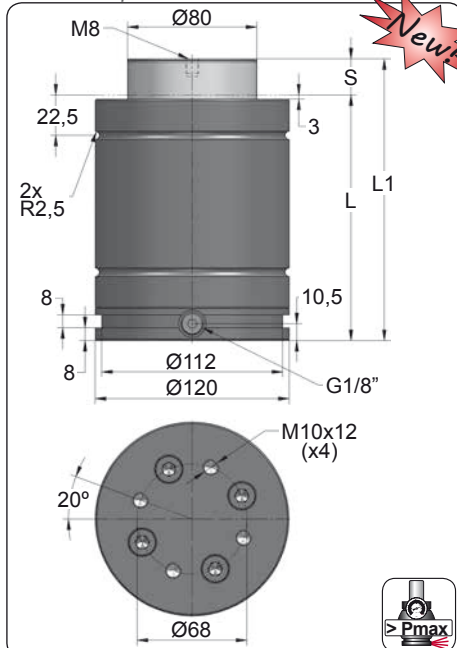


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CS-KC 11800 010 V1	10	120	110	7.36
CS-KC 11800 016 V1	16	146	130	8.03
CS-KC 11800 025 V1	25	175	150	8.76
CS-KC 11800 032 V1	32	207	175	9.59
CS-KC 11800 040 V1	40	240	200	10.43
CS-KC 11800 050 V1	50	280	230	11.45
CS-KC 11800 065 V1	65	340	275	12.98



CODE				
	bar	psi	daN	daN
-----	---	---	---	---
CS-KC 11800 050 V1	0	0	---	---

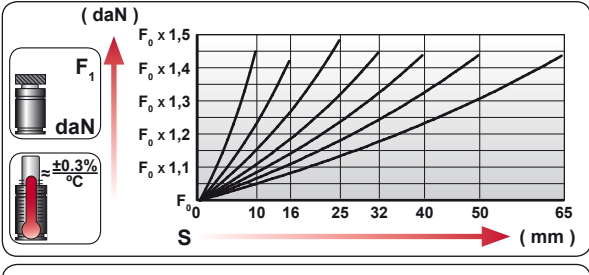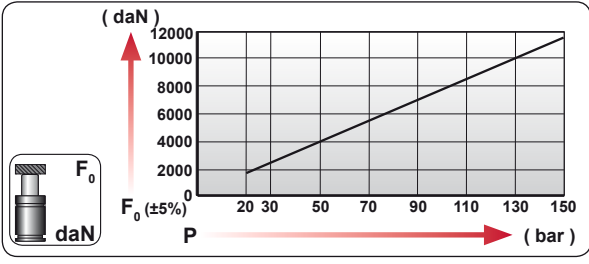

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO	F <sub>0</sub> daN	S mm
CS-KC 11800 50			
CS-KC 11800 050 V1			

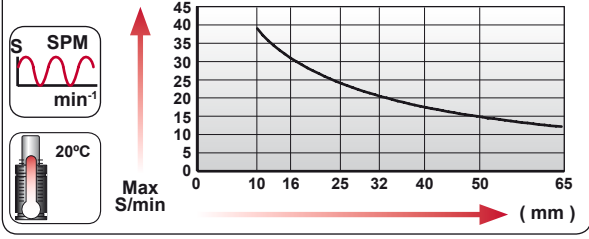

	S <sub>max</sub> 100%	V	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub>	T <sub>max</sub>	
--	-----------------------	---	-------------------------	-------------------------	------------------	------------------	--

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	bar psi	bar psi	°C °F	°C °F	
			20 290	150 2175	0 32	80 176	

# CS-KC 11800 V1 MOUNTS

Power Compact Stroke

## CS-KC

## CS





CODE				
		bar	psi	daN
CS-KC 11800 050 V1		0	0	---

CODE				
		bar	psi	daN
CS 11800 050 V1		150	2175	11780
				17145

## C20-120

ISO 10000, NAMUR, VDI, EM24.54.815.G, EM24.54.700/F

## KC 11800

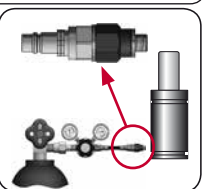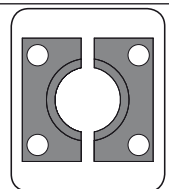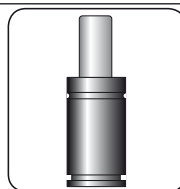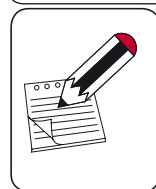

CODE	CS-KC 11800 050 V1	KIT S-XXXXXXX	C20-120	SKK 12R 1/8
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA