

Terminal Boxes

Aluminium Range

Aluminium terminal box | HALP

IP 66, 67



Material:

Aluminium alloy AISI 12.

Gasket:

Standard supply fitted with a polyurethane gasket. Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance:

-30°C to +80°C.

Protection:

IP 66, 67.

Finish:

RAL 7001.

Approvals:

CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery:

Body, cover and cover screws made of stainless steel.




IP 66, 67

Box dimension			Item no.
H	W	D	
45	50	30	HALP050503GE
64	58	36	HALP060604GE
64	98	36	HALP061004GE
64	150	36	HALP061504GE
80	75	57	HALP080806GE
80	125	57	HALP081306GE
80	175	57	HALP081806GE
80	250	57	HALP082506GE
122	122	80	HALP121208GE
122	122	90	HALP121209GE
122	220	80	HALP122208GE
122	220	90	HALP122209GE
122	360	80	HALP123608GE
160	160	90	HALP161609GE
160	260	90	HALP162609GE
160	360	90	HALP163609GE
160	560	90	HALP165609GE
230	200	110	HALP232011GE
230	330	110	HALP233311GE
230	330	180	HALP233318GE
230	400	110	HALP234011GE
230	600	110	HALP236011GE



Dimensional drawing | HALP

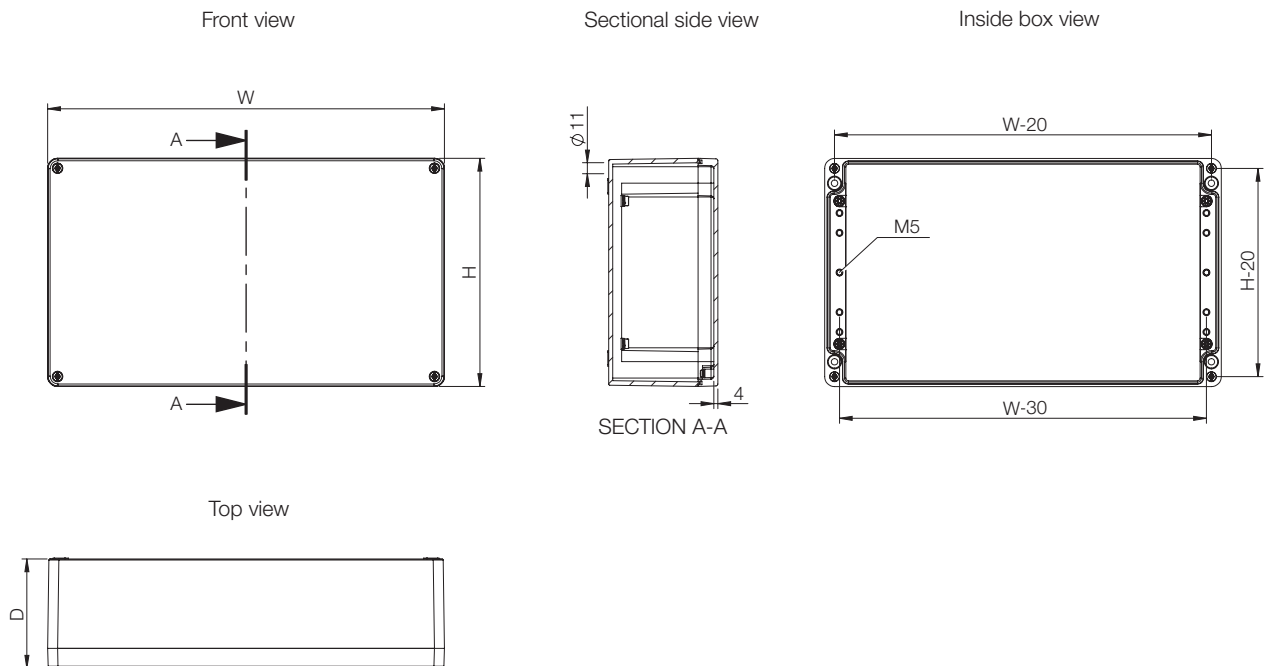

Terminal Boxes

Aluminium Range

Accessories

HALP Mounting plate, HMP

Description: Steel mounting plate for HALP boxes.

Material: 1.5 mm galvanized steel, 2.5 mm for HMP1656E and HMP2360E.

Pack quantity: 1 piece.

Box dimension		Mounting plate dimensions		Item no.
H	W	h	w	
64	58	54	48	HMP0606E
64	98	54	88	HMP0610E
64	150	54	140	HMP0615E
80	75	69	64	HMP0808E
80	125	69	114	HMP0813E
80	175	69	164	HMP0818E
80	250	69	239	HMP0825E
122	122	108	107	HMP1212E
122	220	108	204	HMP1222E
122	360	108	343	HMP1236E
160	160	145	143	HMP1616E
160	260	145	243	HMP1626E
160	360	145	343	HMP1636E
160	560	145	543	HMP1656E
230	200	214	183	HMP2320E
230	330	214	313	HMP2333E
230	400	214	383	HMP2340E
230	600	214	583	HMP2360E



Hinges, HHI

Description: Using this accessory the cover can be hinged. 150° opening. Machining is required.

Material: Aluminium.

For box: HHI02: HALP080806GE to HALP082506GE.
HHI03: HALP121208GE to HALP236011GE.

Pack quantity: Set of 2 hinges in HHI02, and 3 hinges in HHI03. Mounting accessories are included.

Item no.
HHI02
HHI03

Internal hinges available on request.

