

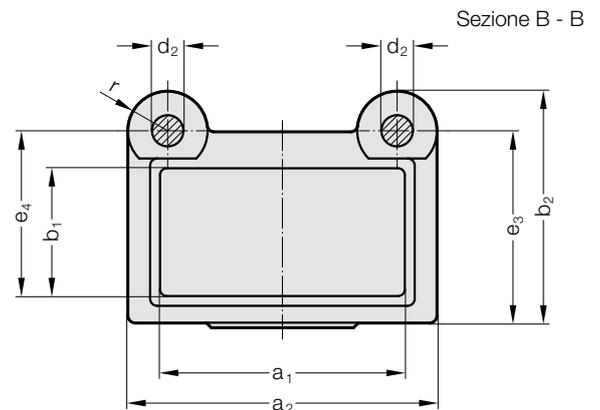



PORTASTAMPO CON GUIDE A COLONNA

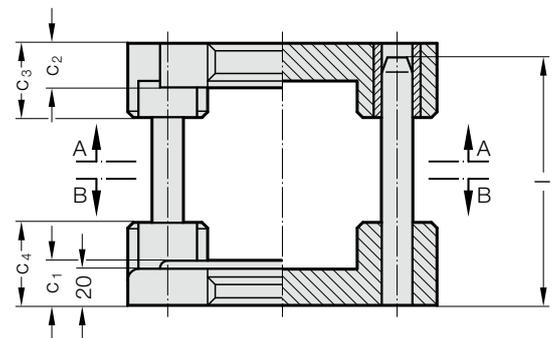

201.33.

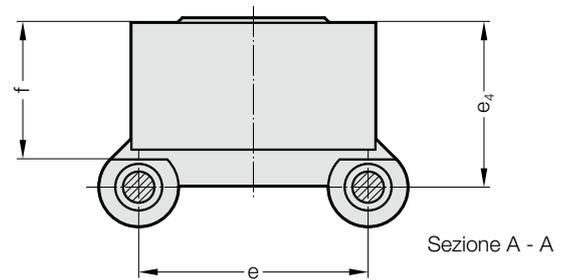

Tipo di guida

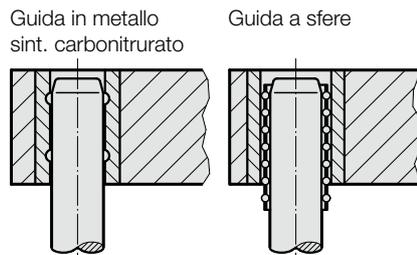

N. d'ordine Parte 2
Senza filettatura
per il codolo nella
piastra superiore



201.33. Portastampo con guide a colonna

N. d'ordine parte 1*	Superficie di lavoro															
	$a_1 \times b_1$	a_2	b_2	c_1	c_2	c_3	c_4	d_2	e	e_3	e_4	f	l	r		
201.33.063.050.□□□.□□	63 x 50	116	110	25	25	40	45	16	72	88	74	57	125 - 355	22		
201.33.080.060.□□□.□□	80 x 60	116	117	25	25	40	45	20	72	95	81	62	160 - 400	22		

*N. d'ordine parte 2 = integrare sistema di guida e tipo/lunghezza della guida a colonna
 Per un esempio di ordinazione vedere l'inizio del capitolo A Portastampi in ghisa