
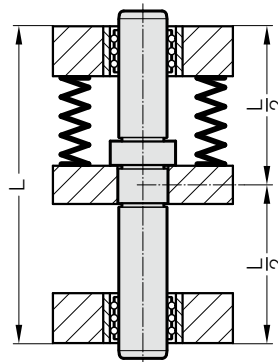


DEMOUNTABLE GUIDE PILLAR WITH CENTRE FIXING

2020.63.

Mounting example

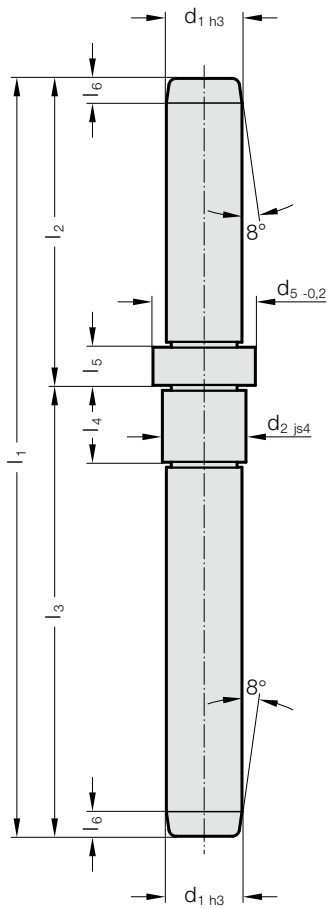

Material:

Steel, surface hardened

Surface hardness: 62 + 2 HRC, Hardness penetration 1 ± 0,2 mm

Execution:

precision ground

Note:

For press fit into register bore N5.

Bending equation see at the beginning of chapter D.

Matching guide combinations, see selection matrix at the beginning of chapter D.

2020.63. Demountable guide pillar with centre fixing

Order No	d ₁	d ₂	d ₅	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆
2020.63.012.042.074	12	13	15.9	116	42	74	12.5	5	3
2020.63.016.064.094	16	18	21.9	158	64	94	16	8	5