


带安全环凹槽的滚珠轴承保持架, 黄铜

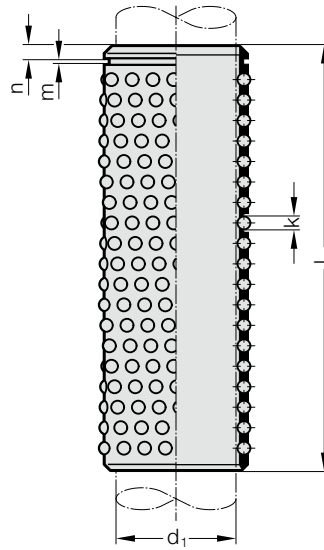

206.71.



材料:

笼: 黄铜

球体: 钢, 硬化处理根据 DIN 5401

说明:

规格在直径 10 以上的滚珠轴承罩配有安全环 DIN 471 (206.72.) 的凹槽。

☐ 滚珠导向类型见D章开头。

☐ 轴承寿命和动态负荷指数见D章节的末尾部分。

l = 订购额定长度

l₁ = 生产长度

206.71. 带安全环凹槽的滚珠轴承保持架, 黄铜

d ₁	8	10	11	12	15	16	19	20	24	25	30	32	38	40	48	50	60	63	80	
k	1.5	2			3		3		3		4		4		4		4		6	
n			1.1		1.6		1.6		1.6		2.1		2.1		2.1		2.1		3	
m			1.1		1.3		1.3		1.6		1.85		1.85		2.15		2.65		3.15	
l/l ₁	总滚珠数量																			
24 / 24			96		64		80													
28 / 27			112																	
28 / 28					80		100													
31 / 30			128																	
31 / 32					96		120		120											
40 / 39	136		176																	
40 / 40					128		160		160		120									
45 / 44					144		180		180											
45 / 45			208								140		168							
50 / 48			224				200													
50 / 50											160		192		224					
50 / 52					176				220											
56 / 55											180		216		252					
56 / 56					192		240		240											
56 / 57			272																	
63 / 64					224		280		280											
63 / 65											220		264		308					
71 / 70											240		288		336					
71 / 72					256		320		320											
80 / 80							360		360		280		336		392		448			
95 / 95											340		408		476		544			
95 / 96							440		440											
105 / 104									480											
105 / 105											380		456		532		608			
120 / 119																			540	
120 / 120									560		440		528		616		704			
140 / 140											520		624		728		832		648	
160 / 160											600		720		840		960			
160 / 161																			756	
180 / 180													816		952		1,088			
180 / 182																			864	
200 / 200													912		1,064		1,216			
200 / 203																			972	
240 / 238																			1,152	
240 / 240													1,104		1,288		1,472			

订购示例:

带安全环凹槽的滚珠轴承保持架, 黄铜 = 206.71.
 导向装置直径 d₁ 30 mm = 030.
 滚珠轴承保持架的订购额定长度 l 120 mm = 120
 订购编号 = 206.71. 030. 120