


快速更换型冲头，毛坯，轻载 荷用

2202.

 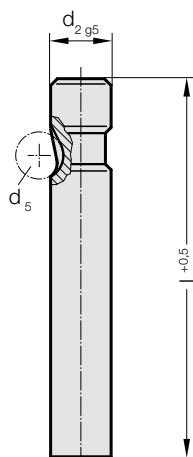


2202. 快速更换型冲头，毛坯，轻载 荷用

d ₂ / 订购数字	d ₅	l / (订货字母)	63 (C)	71 (D)	80 (E)	90 (F)	100 (G)	110 (H)	125 (J)	140 (K)	150 (L)	175 (M)	200 (N)
6 / (1)	6		●	●	●	●	●						
10 / (2)	8		●	●	●	●	●	●					
13 / (3)	8		●	●	●	●	●	●	●	●	●	●	
16 / (4)	8		●	●	●	●	●	●	●	●	●	●	
20 / (5)	8		●	●	●	●	●	●	●	●	●	●	
25 / (6)	8		●	●	●	●	●	●	●	●	●	●	●
32 / (7)	8			●	●	●	●	●	●	●	●	●	●
38 / (8)	8				●	●	●	●	●	●	●	●	●

订购示例:

2202.7G



长度: l
100 mm
直径: d₂
32 mm
型号:
轻型
规格:
毛坯
冲头:

订货字母
= (G)
订购数字
= (7)
订购数字
= (2)
订购数字
= (0)
无弹顶销
= 22

材料:

HSS
硬度 62 ± 2 HRC

结构:

精磨凸模柄部。
特别尺寸请洽询