


快速更换型冲头，毛坯，重载荷用

2203.

 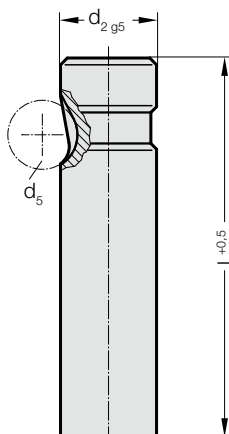


2203. 快速更换型冲头，毛坯，重载荷用

d ₂ / 订购数字	d ₅	l / (订货字母)	63 (C)	71 (D)	80 (E)	90 (F)	100 (G)	110 (H)	125 (J)	140 (K)	150 (L)	175 (M)	200 (N)
10 / (2)	10		●	●	●	●	●	●	●				
13 / (3)	12		●	●	●	●	●	●	●	●	●	●	
16 / (4)	12		●	●	●	●	●	●	●	●	●	●	●
20 / (5)	12		●	●	●	●	●	●	●	●	●	●	●
25 / (6)	12			●	●	●	●	●	●	●	●	●	●
32 / (7)	12			●	●	●	●	●	●	●	●	●	●
40 / (9)	12				●	●	●	●	●	●	●	●	●

订购示例:

2 2 0 3 . 7 G



长度: l
100 mm
直径: d₂
32 mm
型号:
重型
规格:
毛坯
冲头:
无弹顶销

订货字母
= (G)
订购数字
= (7)
订购数字
= (3)
订购数字
= (0)
= 22

材料:

HSS
硬度 62 ± 2 HRC

结构:

精磨凸模柄部。
特别尺寸请洽询