


球锁导正销，带有圆锥形尖部，轻载荷用

2262.

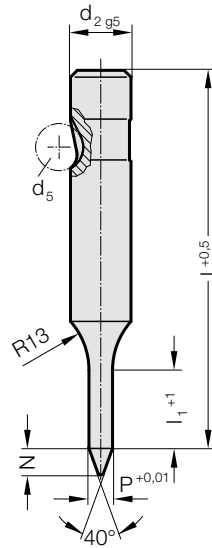


2262. 球锁导正销，带有圆锥形尖部，轻载荷用

d ₂ / 订购数字	d ₅	P	l ₁ / 订购数字	N	l (订货字母)	71 (D)	80 (E)	90 (F)	100 (G)	110 (H)	125 (J)	140 (K)	150 (L)
10 / (2)	8	5,9 - 9,9	19(2)	8		●	●	●	●	●			
13 / (3)	8	9,9 - 12,9	19(2)	10		●	●	●	●	●	●	●	
16 / (4)	8	12,9 - 15,9	25(3)	15		●	●	●	●	●	●	●	●
20 / (5)	8	15,9 - 19,9	25(3)	20		●	●	●	●	●	●	●	●
25 / (6)	8	19,9 - 24,9	25(3)	25		●	●	●	●	●	●	●	●
32 / (7)	8	24,9 - 31,9	25(3)	30		●	●	●	●	●	●	●	●
38 / (8)	8	31,9 - 37,9	30(4)	35			●	●	●	●	●	●	●

订购示例:

2 2 6 2 . 4 G 3 . 1 4 1 0

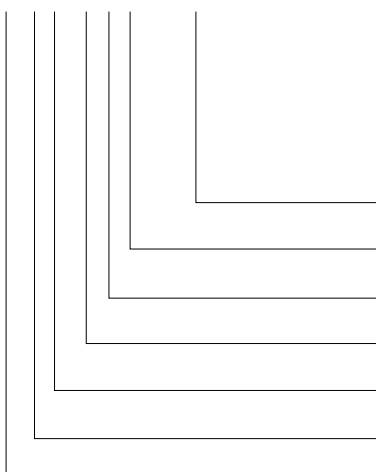

形状: 圆形
 P = ∅ 14,1 mm
 冲裁凸模长度: l₁
 25 mm
 长度: l
 100 mm
 直径: d₂
 16 mm
 型号:
 轻型
 规格:
 圆锥尖部导正销
 冲头:
 无弹顶销

= 1410
 订购数字
 = (3)
 订货字母
 = (G)
 订购数字
 = (4)
 订购数字
 = (2)
 订购数字
 = (6)
 = 22

材料:

HSS
 硬度 62 ± 2 HRC

结构:

精磨柄部和导正销。
 特别尺寸请洽询