

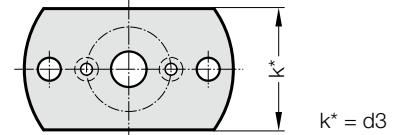
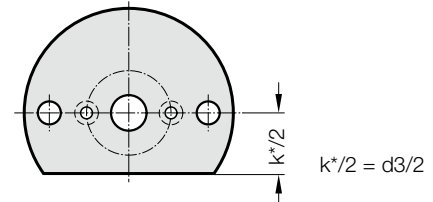


# DISCO DI AGGIUSTAGGIO

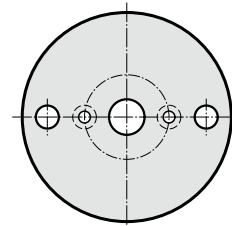

2441.11.3.

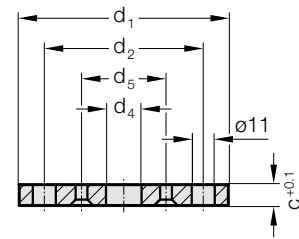

**Materiale:**

C45 o similare

**Nota:**

2441.11.3.□□□

Disco di aggiustaggio

2441.11.3.□□□.1

Disco di aggiustaggio con rifilatura laterale piana

2441.11.3.□□□.2

Disco di aggiustaggio con rifilature bilaterali parallele

**2441.11.3. Disco di aggiustaggio**

N. d'ordine	d <sub>1</sub>	d <sub>2</sub>	d <sub>4</sub>	d <sub>5</sub>	c	k
2441.11.3.100	100	76	17	40,5	9,8	-
2441.11.3.100.1	100	76	17	40,5	9,8	58
2441.11.3.100.2	100	76	17	40,5	9,8	58
2441.11.3.105	105	76	18	40,5	5,5	-
2441.11.3.120	120	96	17	50,5	9,8	-
2441.11.3.120.1	120	96	17	50,5	9,8	78
2441.11.3.120.2	120	96	17	50,5	9,8	78
2441.11.3.125	125	96	18	50,5	5,5	-