


INDUCTIVE PROXIMITY SWITCH



2443.14.00.60.18.044

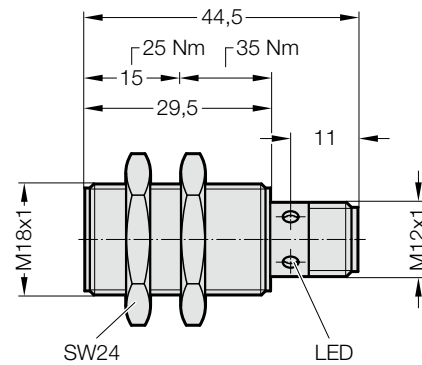

Technical data:

Rated operating voltage U_e : 24 V DC
Operating Voltage U_s : 10 - 30 V DC
No load current I_0 damped/undamped: $\leq 10 \text{ mA} / \leq 3 \text{ mA}$
Repeat accuracy R: max. (% v. Sr) 5%
Ambient temperature T_a : -25 to +70°C
Switching frequency f : max. 1000 Hz
Degree of protection to IEC 60529: IP 67
Casing material: CuZn
Connection: plug connector
Approvals: UL

2443.14.00.60.18.044

Inductive proximity switch