
 


PRESSURE BOLT WITH BASE, ACCORDING TO VW


2446.10.55.03.

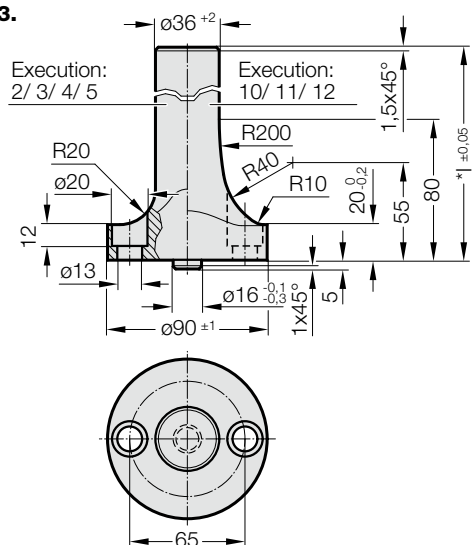


2446.10.55.02. / 2446.10.55.10. / 2446.10.55.11.



2446.10.55.04.

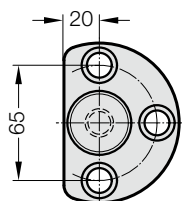

2446.10.55.05. / 2446.10.55.12.

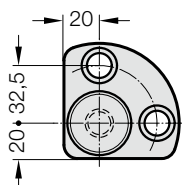

2446.10.55. Pressure bolt with base, according to VW

Order No	Shape	b	l*	Gradation
2446.10.55.02.150	2	40	150 - 360	1
2446.10.55.03.150	3	-	150 - 360	1
2446.10.55.04.150	4	-	150 - 360	1
2446.10.55.05.150	5	-	150 - 360	1
2446.10.55.10.150	10	60	150 - 360	1
2446.10.55.11.150	11	40	150 - 360	1
2446.10.55.12.150	12	-	150 - 360	1

*to customer's specifications!

Ordering Code (example):

Pressure bolt with base, according to VW = 2446.10.55.
 Execution Shape 4 = 04.
 Length l 150 mm = 150
 Order No = 2446.10.55. 04. 150