


冲头, 毛坯, 带弹顶销, ISO 8020

2701.

 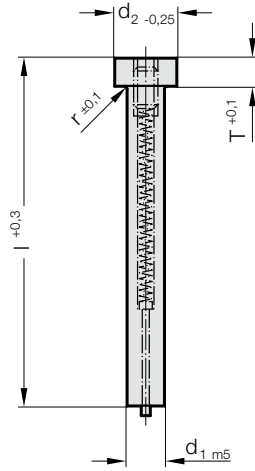


2701. 冲头, 毛坯, 带弹顶销, ISO 8020

d ₁ / 订购数字	d ₂	r	T	l / (订货字母)	71 (D)	80 (E)	90 (F)	100 (G)	120 (J)
5 / (3)	8	0.3	5		●	●	●	●	●
6 / (4)	9	0.3	5		●	●	●	●	●
8 / (5)	11	0.3	5		●	●	●	●	●
10 / (6)	13	0.3	5		●	●	●	●	●
13 / (7)	16	0.4	5		●	●	●	●	●
16 / (8)	19	0.4	5		●	●	●	●	●
20 / (9)	23	0.4	5		●	●	●	●	●
25 / (10)	28	0.4	5		●	●	●	●	●
32 / (11)	35	0.4	5		●	●	●	●	●

订购示例:

2701.8G



长度: l
100 mm
直径: d₁
16 mm
型号:
ISO
规格:
毛坯
冲头:
有压紧销

订货字母
= (G)
订购数字
= (8)
订购数字
= (1)
订购数字
= (0)
= 27

材料:

HSS

硬度:

杆部 64 ± 2 HRC

头部 52 ± 5 HRC

结构:

热锻冲头, 支承面和体经过最为精密的磨削。

特别生产请咨询。