

符合DIN 59350带有加工余量的精密扁钢和精密方钢

材料:

1.2842 / 90 MnCrV

冷锻模钢

结构:

厚度已精磨, 宽度已打磨或铣削, 长度已加工

说明:


● = 适用于 500 mm 和 1000 mm 长度

■ = 仅适用于 1000 mm 长度

2923.2842.



我们为您提供
BÖHLER
原装质量

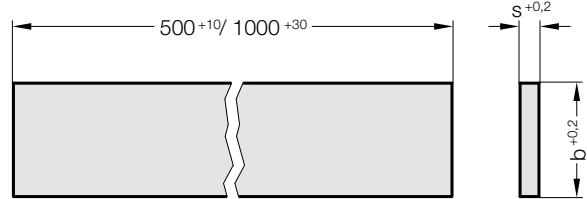

2923.2842. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	2.2	3.2	4.2	5.2	6.2	8.2	10.4	12.4	15.4	16.4	20.4	25.4	30.4	32.4	40.4	50.4	60.4	80.4	100.4
10.3	○	○	○	○	○	○													
10.4							●												
12.4								●											
15.3	○	○	○	○	○	○	○	○											
16.4										○									
20.3	○	○	●	●	●	●	●	●	●	○									
20.4											●								
25.3	○	○	●	●	●	●	●	●	●	○	●								
25.4												●							
30.3	○	○	●	●	●	●	●	●	●	○	●	●							
30.4													●						
32.3			○	○	○	○	○	○	○	○	○	○							
32.4														○					
40.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○					
40.4															●				
50.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●				
50.4																●			
60.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●			
60.4																	●		
63.3			○	○	○	○	○	○	○	○	○	○	○	○	○	○			
70.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●			
80.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●			
80.4																		●	
100.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	
100.4																			●
120.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
125.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
150.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
160.3			●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
180.3			●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
200.3	○	○	●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
250.3			●	●	●	●	●	●	●	○	●	●	●	○	●	●		●	●
300.3						●	●	●	●	○	●	●	●					●	●

订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2842.
宽 B	30.3 mm	= 030.
厚度 S	2.2 mm	= 002.
长度 L	1000 mm	= 1000
订购编号		= 2923.2842. 030. 002. 1000