

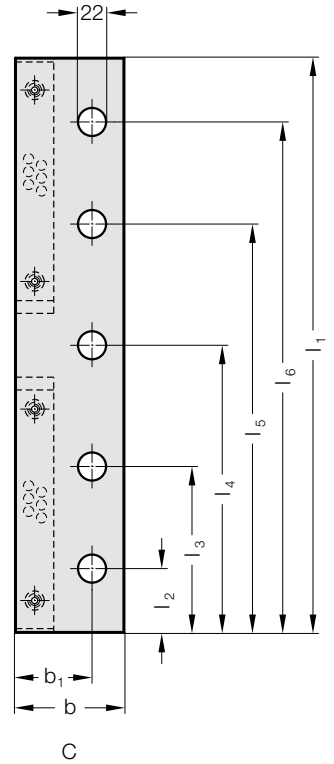
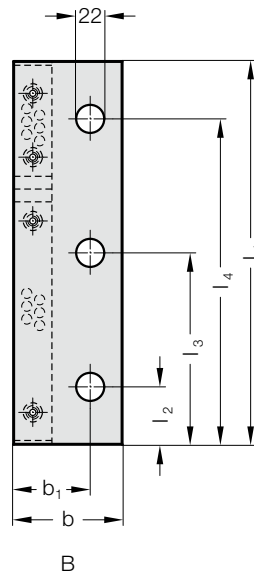


RETAINING PLATE WITH SLIDING PAD, STEEL / BRONZE WITH SOLID LUBRICANT, ACCORDING TO VW

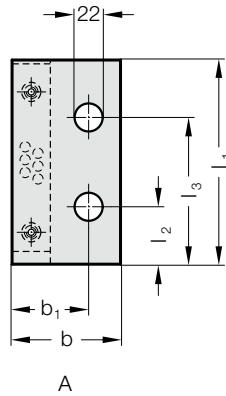

2961.74.55.

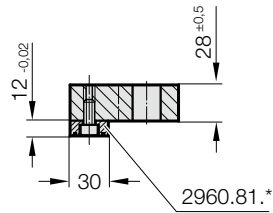

Material:

Retaining plate: Steel
 Sliding pad: Bronze with solid lubricant,
 low-maintenance

Execution:



The retaining plate with sliding pad consists of:
 - Retaining plate
 - Sliding pad 2960.81.*
 - Cylindrical screw according to DIN EN ISO 4762 M8x16 (x2, x4)

Note:

Supplied without screws.
 Retaining plate cannot be ordered separately.
 *Sliding pad 2960.81. can be ordered separately in case of wear.

Fixing:

Use socket cap screws DIN EN ISO 4762 M20.

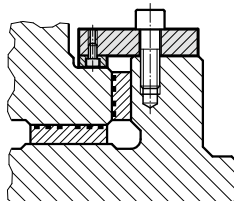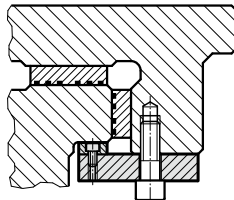

RETAINING PLATE WITH SLIDING PAD, STEEL / BRONZE WITH SOLID LUBRICANT, ACCORDING TO VW

2961.74.55. Retaining plate with sliding pad, Steel / Bronze with solid lubricant, according to VW

Order No	Shape	b	b ₁	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆	Number of screw holes
2961.74.55.085.28.160	A	85	60	160	45	115	-	-	-	2
2961.74.55.085.28.200	A	85	60	200	45	155	-	-	-	2
2961.74.55.085.28.250	B	85	60	250	45	125	225	-	-	3
2961.74.55.085.28.300	B	85	60	300	45	150	255	-	-	3
2961.74.55.085.28.350	B	85	60	350	45	175	305	-	-	3
2961.74.55.085.28.400	C	85	60	400	45	125	200	275	355	5
2961.74.55.085.28.450	C	85	60	450	50	130	225	320	400	5
2961.74.55.085.28.500	C	85	60	500	50	130	250	370	450	5
2961.74.55.125.28.160	A	125	75	160	45	115	-	-	-	2
2961.74.55.125.28.200	A	125	75	200	45	155	-	-	-	2
2961.74.55.125.28.250	B	125	75	250	45	125	225	-	-	3
2961.74.55.125.28.300	B	125	75	300	45	150	255	-	-	3
2961.74.55.125.28.350	B	125	75	350	45	175	305	-	-	3
2961.74.55.125.28.400	C	125	75	400	45	125	200	275	355	5
2961.74.55.125.28.450	C	125	75	450	50	130	225	320	400	5
2961.74.55.125.28.500	C	125	75	500	50	130	250	350	450	5