



# RETAINING PLATE, BRONZE WITH SOLID LUBRICANT



2961.78.



## Mounting example

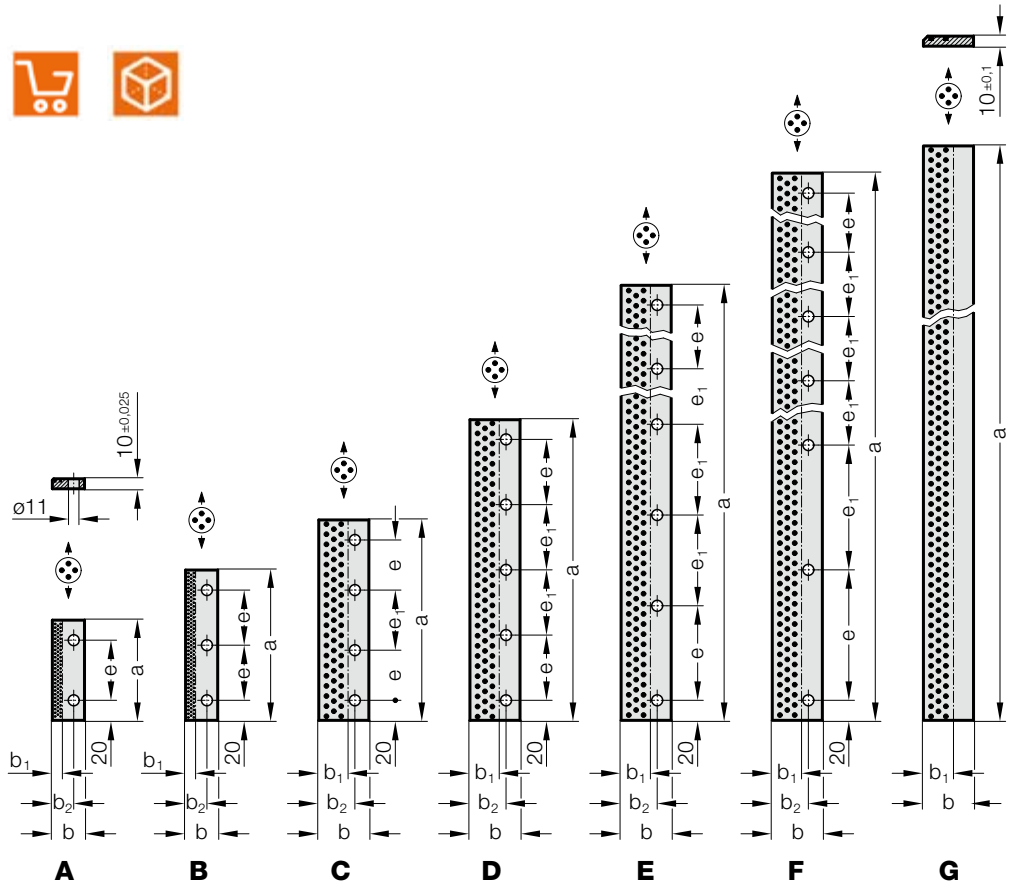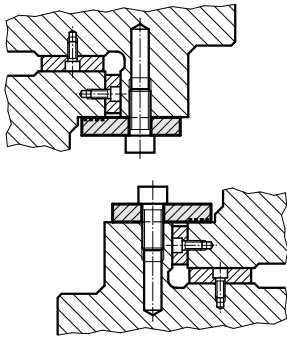

## Material:

Bronze with solid lubricant, oilless lubricating

## Note:

Screws are not included.

## Fixing:

Use socket cap screws  
DIN EN ISO 4762 M10.

## 2961.78. Retaining plate, Bronze with solid lubricant

Order No	Shape	a	b	b <sub>1</sub>	b <sub>2</sub>	e	e <sub>1</sub>	Number of screw holes
2961.78.032.0100	A	100	32	10	21	60	-	2
2961.78.032.0150	B	150	32	10	21	55	-	3
2961.78.032.0160	B	160	32	10	21	60	-	3
2961.78.050.0200	C	200	50	30	36	50	60	4
2961.78.050.0250	C	250	50	30	36	70	70	4
2961.78.050.0300	D	300	50	30	36	65	65	5
2961.78.050.0350	D	350	50	30	36	80	75	5
2961.78.050.0400	D	400	50	30	36	90	90	5
2961.78.050.0500	E	500	50	30	36	95	90	6
2961.78.050.0600	E	600	50	30	36	115	110	6
2961.78.050.0800	F	800	50	30	36	130	125	7
2961.78.050.0605	G	605	50	30	36	-	-	-
2961.78.050.1005	G	1,005	50	30	36	-	-	-