


GRAFİTLİ L PLAKA, BRONZ KENDİNDEN YAĞLAMALI

2962.72.

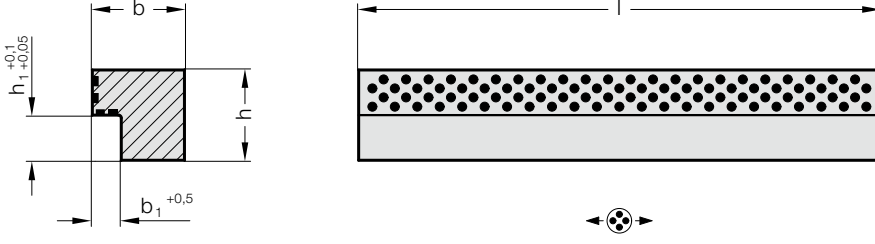

Malzeme:

Bronz Kendinden Yağlamalı

2962.72. Grafitli L Plaka, Bronz Kendinden Yağlamalı

| Sipariş No. | b | h | b ₁ | h ₁ | l |
|----------------------|----|----|----------------|----------------|-----|
| 2962.72.015.012.0205 | 15 | 12 | 5 | 5 | 205 |
| 2962.72.020.022.0205 | 20 | 22 | 5 | 7 | 205 |
| 2962.72.020.017.0205 | 20 | 17 | 5 | 7 | 205 |
| 2962.72.020.017.0320 | 20 | 17 | 5 | 7 | 320 |
| 2962.72.020.022.0320 | 20 | 22 | 5 | 7 | 320 |
| 2962.72.028.027.0205 | 28 | 27 | 8 | 10 | 205 |
| 2962.72.028.036.0205 | 28 | 36 | 8 | 10 | 205 |
| 2962.72.028.046.0205 | 28 | 46 | 8 | 10 | 205 |
| 2962.72.028.027.0320 | 28 | 27 | 8 | 10 | 320 |
| 2962.72.028.036.0320 | 28 | 36 | 8 | 10 | 320 |
| 2962.72.028.046.0320 | 28 | 46 | 8 | 10 | 320 |
| 2962.72.028.027.0605 | 28 | 27 | 8 | 10 | 605 |
| 2962.72.028.036.0605 | 28 | 36 | 8 | 10 | 605 |
| 2962.72.028.046.0605 | 28 | 46 | 8 | 10 | 605 |
| 2962.72.040.066.0205 | 40 | 66 | 12 | 22 | 205 |
| 2962.72.040.066.0320 | 40 | 66 | 12 | 22 | 320 |
| 2962.72.040.066.0605 | 40 | 66 | 12 | 22 | 605 |
| 2962.72.040.086.0205 | 40 | 86 | 12 | 26 | 205 |
| 2962.72.040.086.0320 | 40 | 86 | 12 | 26 | 320 |
| 2962.72.040.086.0605 | 40 | 86 | 12 | 26 | 605 |