


# FÜHRUNGSLEISTE MIT VIER GLEITFLÄCHEN, BRONZE MIT FESTSCHMIERSTOFF

2962.74.

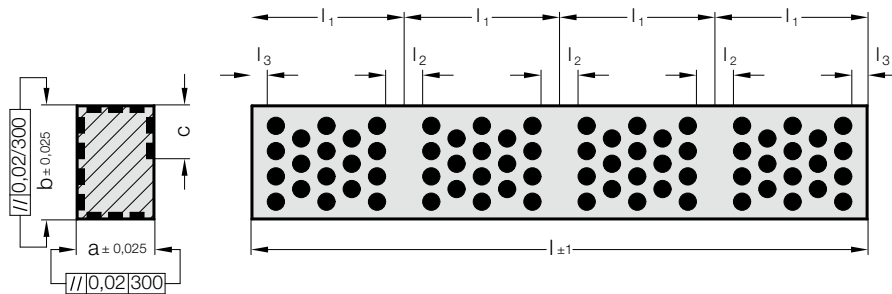

## Werkstoff:

Bronze mit Festschmierstoff, wartungsarm

## 2962.74. Führungsleiste mit vier Gleitflächen, Bronze mit Festschmierstoff

| Bestell-Nummer      | a    | b    | c  | l   | l <sub>1</sub> | l <sub>2</sub> | l <sub>3</sub> |
|---------------------|------|------|----|-----|----------------|----------------|----------------|
| 2962.74.015.010.075 | 10,3 | 15,3 | 6  | 75  | 25             | 6              | 3              |
| 2962.74.015.010.100 | 10,3 | 15,3 | 6  | 100 | 25             | 6              | 3              |
| 2962.74.015.010.125 | 10,3 | 15,3 | 6  | 125 | 25             | 6              | 3              |
| 2962.74.015.010.150 | 10,3 | 15,3 | 6  | 150 | 25             | 6              | 3              |
| 2962.74.015.010.175 | 10,3 | 15,3 | 6  | 175 | 25             | 6              | 3              |
| 2962.74.015.010.200 | 10,3 | 15,3 | 6  | 200 | 25             | 6              | 3              |
| 2962.74.015.010.225 | 10,3 | 15,3 | 6  | 225 | 25             | 6              | 3              |
| 2962.74.015.010.250 | 10,3 | 15,3 | 6  | 250 | 25             | 6              | 3              |
| 2962.74.015.010.275 | 10,3 | 15,3 | 6  | 275 | 25             | 6              | 3              |
| 2962.74.015.010.300 | 10,3 | 15,3 | 6  | 300 | 25             | 6              | 3              |
| 2962.74.025.015.105 | 15,3 | 25,3 | 8  | 105 | 35             | 8              | 4              |
| 2962.74.025.015.140 | 15,3 | 25,3 | 8  | 140 | 35             | 8              | 4              |
| 2962.74.025.015.175 | 15,3 | 25,3 | 8  | 175 | 35             | 8              | 4              |
| 2962.74.025.015.210 | 15,3 | 25,3 | 8  | 210 | 35             | 8              | 4              |
| 2962.74.025.015.245 | 15,3 | 25,3 | 8  | 245 | 35             | 8              | 4              |
| 2962.74.025.015.280 | 15,3 | 25,3 | 8  | 280 | 35             | 8              | 4              |
| 2962.74.025.015.315 | 15,3 | 25,3 | 8  | 315 | 35             | 8              | 4              |
| 2962.74.025.015.350 | 15,3 | 25,3 | 8  | 350 | 35             | 8              | 4              |
| 2962.74.025.015.385 | 15,3 | 25,3 | 8  | 385 | 35             | 8              | 4              |
| 2962.74.025.015.420 | 15,3 | 25,3 | 8  | 420 | 35             | 8              | 4              |
| 2962.74.025.015.455 | 15,3 | 25,3 | 8  | 455 | 35             | 8              | 4              |
| 2962.74.025.015.490 | 15,3 | 25,3 | 8  | 490 | 35             | 8              | 4              |
| 2962.74.035.025.135 | 25,3 | 35,3 | 12 | 135 | 45             | 10             | 5              |
| 2962.74.035.025.180 | 25,3 | 35,3 | 12 | 180 | 45             | 10             | 5              |
| 2962.74.035.025.225 | 25,3 | 35,3 | 12 | 225 | 45             | 10             | 5              |
| 2962.74.035.025.270 | 25,3 | 35,3 | 12 | 270 | 45             | 10             | 5              |
| 2962.74.035.025.315 | 25,3 | 35,3 | 12 | 315 | 45             | 10             | 5              |
| 2962.74.035.025.360 | 25,3 | 35,3 | 12 | 360 | 45             | 10             | 5              |
| 2962.74.035.025.405 | 25,3 | 35,3 | 12 | 405 | 45             | 10             | 5              |
| 2962.74.035.025.450 | 25,3 | 35,3 | 12 | 450 | 45             | 10             | 5              |
| 2962.74.035.025.495 | 25,3 | 35,3 | 12 | 495 | 45             | 10             | 5              |
| 2962.74.045.035.165 | 35,3 | 45,3 | 16 | 165 | 55             | 12             | 6              |
| 2962.74.045.035.220 | 35,3 | 45,3 | 16 | 220 | 55             | 12             | 6              |
| 2962.74.045.035.275 | 35,3 | 45,3 | 16 | 275 | 55             | 12             | 6              |
| 2962.74.045.035.330 | 35,3 | 45,3 | 16 | 330 | 55             | 12             | 6              |
| 2962.74.045.035.385 | 35,3 | 45,3 | 16 | 385 | 55             | 12             | 6              |
| 2962.74.045.035.440 | 35,3 | 45,3 | 16 | 440 | 55             | 12             | 6              |
| 2962.74.045.035.495 | 35,3 | 45,3 | 16 | 495 | 55             | 12             | 6              |