


LISTWA PROWADZĄCA Z CZTEREMA POWIERZCHNIAMI ŚLIZGOWYMI, BRĄZ Z WKŁADKAMI GRAFITOWYMI

2962.74.

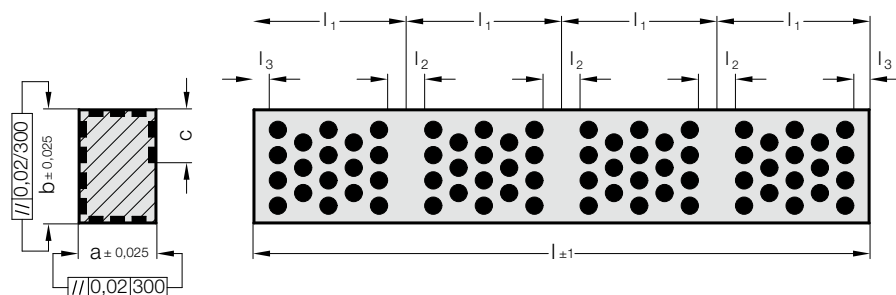

Material:

Brąz z wkładkami grafitowymi, nie wymaga stałej konserwacji

2962.74. Listwa prowadząca z czterema powierzchniami ślizgowymi, Brąz z wkładkami grafitowymi

Numer katalogowy	a	b	c	l	l ₁	l ₂	l ₃
2962.74.015.010.075	10,3	15,3	6	75	25	6	3
2962.74.015.010.100	10,3	15,3	6	100	25	6	3
2962.74.015.010.125	10,3	15,3	6	125	25	6	3
2962.74.015.010.150	10,3	15,3	6	150	25	6	3
2962.74.015.010.175	10,3	15,3	6	175	25	6	3
2962.74.015.010.200	10,3	15,3	6	200	25	6	3
2962.74.015.010.225	10,3	15,3	6	225	25	6	3
2962.74.015.010.250	10,3	15,3	6	250	25	6	3
2962.74.015.010.275	10,3	15,3	6	275	25	6	3
2962.74.015.010.300	10,3	15,3	6	300	25	6	3
2962.74.025.015.105	15,3	25,3	8	105	35	8	4
2962.74.025.015.140	15,3	25,3	8	140	35	8	4
2962.74.025.015.175	15,3	25,3	8	175	35	8	4
2962.74.025.015.210	15,3	25,3	8	210	35	8	4
2962.74.025.015.245	15,3	25,3	8	245	35	8	4
2962.74.025.015.280	15,3	25,3	8	280	35	8	4
2962.74.025.015.315	15,3	25,3	8	315	35	8	4
2962.74.025.015.350	15,3	25,3	8	350	35	8	4
2962.74.025.015.385	15,3	25,3	8	385	35	8	4
2962.74.025.015.420	15,3	25,3	8	420	35	8	4
2962.74.025.015.455	15,3	25,3	8	455	35	8	4
2962.74.025.015.490	15,3	25,3	8	490	35	8	4
2962.74.035.025.135	25,3	35,3	12	135	45	10	5
2962.74.035.025.180	25,3	35,3	12	180	45	10	5
2962.74.035.025.225	25,3	35,3	12	225	45	10	5
2962.74.035.025.270	25,3	35,3	12	270	45	10	5
2962.74.035.025.315	25,3	35,3	12	315	45	10	5
2962.74.035.025.360	25,3	35,3	12	360	45	10	5
2962.74.035.025.405	25,3	35,3	12	405	45	10	5
2962.74.035.025.450	25,3	35,3	12	450	45	10	5
2962.74.035.025.495	25,3	35,3	12	495	45	10	5
2962.74.045.035.165	35,3	45,3	16	165	55	12	6
2962.74.045.035.220	35,3	45,3	16	220	55	12	6
2962.74.045.035.275	35,3	45,3	16	275	55	12	6
2962.74.045.035.330	35,3	45,3	16	330	55	12	6
2962.74.045.035.385	35,3	45,3	16	385	55	12	6
2962.74.045.035.440	35,3	45,3	16	440	55	12	6
2962.74.045.035.495	35,3	45,3	16	495	55	12	6