


## ZLW-OD – Opposite



- Quick reverse positioning
- Fast right/left adjustment
- Compact and light
- Motor flange for NEMA23 available from stock
- Available as standard and basic version
- Angle flange for fixing
- Max. available stroke length:  
0630 : 1,000 mm  
1040: 1,500 mm
- Max. load radial:  
50 N (0630), 100 N (1040)



**Order key**  
complete ► page 1226

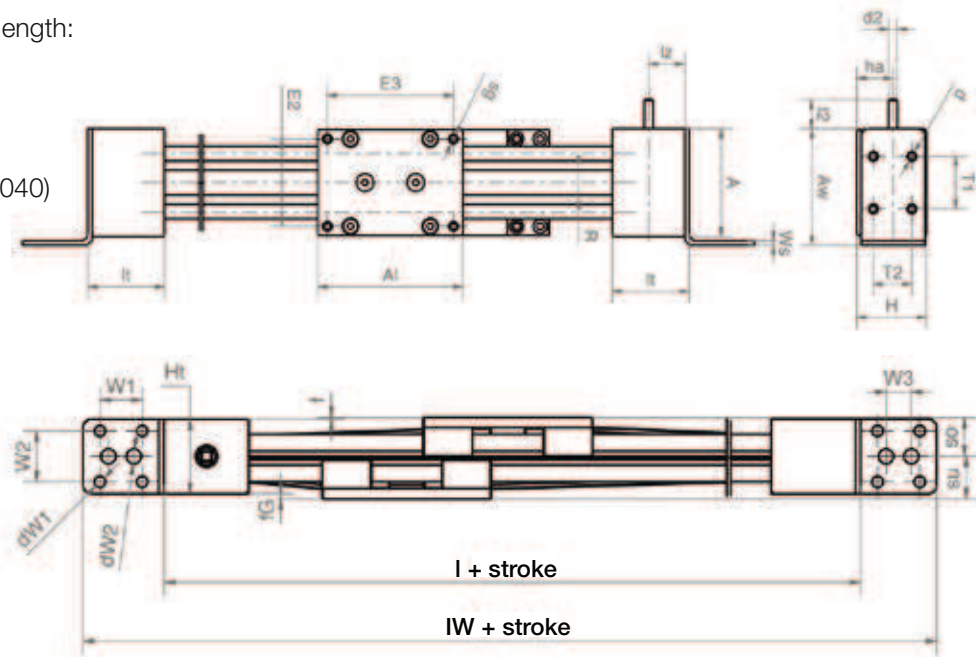

### Dimensions [mm]

Part number	A	AI	H	Ht	E2	E3	I	R	f	fG	lt	sg	ha	l2	d2
	-0.3				±0.15	±0.15		±0.15			±0.3				h9
ZLW-0630-OD*	54	60	31	28	45	51	144	30	3	7	42	M4	14	20	8
ZLW-1040-OD	74	100	45	44	60	87	204	40	1	3	52	M6	22	20	10

Part number	d	SU	SO	T1	T2	lz	Ws	W1	W2	W3	dw1	dw2	IW	AW
Con. dimensions				±0.2	-1.0								±0.25	±0.25
ZLW-0630-OD*	4	21	17	20	21	22	2	20	2	10	5.5	6.6	260	60
ZLW-1040-OD	5	25	23	36	26.5	27	3	25	3	15	6.6	8.8	296	80

\* Basic version: 6 mm square, plastic adapter for pin diameter 10 mm included



**delivery** 2-3 days  
**time**



**prices** price list online  
[www.igus.eu/eu/ZLW-OD](http://www.igus.eu/eu/ZLW-OD)