




Structure – part no.  
SHT-P3-A-2-DX-O

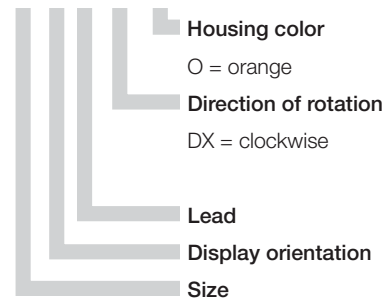

mm

DryLin® SHT

Phone +49 - 22 03 - 96 49-145  
Fax +49 - 22 03 - 96 49-334

igus® GmbH  
51147 Cologne

Internet [www.igus.de](http://www.igus.de)  
E-mail [info@igus.de](mailto:info@igus.de)

### Position indicator

- Plastic digital indicator for adjustment and direct reading of slide position
- 4-digit counter (red digit indicates tenths)
- Counting takes place clockwise
- Colour: Orange

### Installation possibilities



0 grade    90 grade    180 grade    270 grade

### Display orientation




A\*    B    C    D

\* Standard

### Lead

The lead depends on the used spindle.

Lead	for spindle	See in the display after 1 rotation
1	TR 10 x 1	0010
1,5**	TR 10 x 1,5	0015
2	TR 10 x 2	0020
3	TR 10 x 3; TR 12 x 3	0030
4	TR 18 x 4; TR 10 x 2 LR	0040
5	TR 24 x 5	0050
6	TR 10 x 3; TR 12 x 3 LR	0060
8	TR 18 x 4 LR	0080
12	TR 10 x 12	0120
50	TR 10 x 50	0600
100	TR 10 x 100; TR 10 x 50 LR	1000

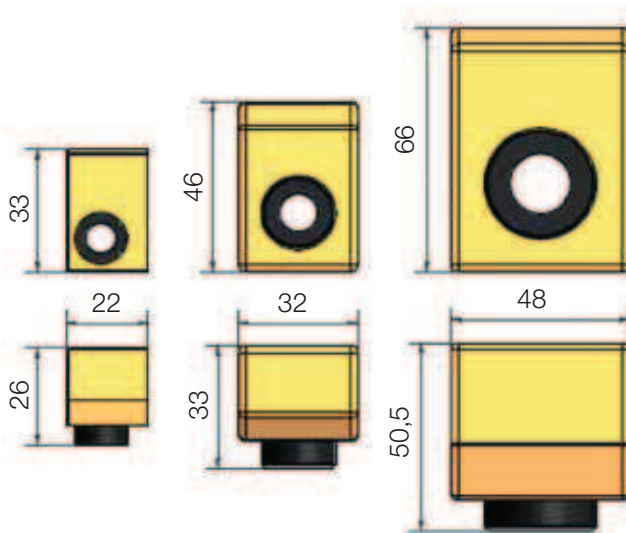

**P1** SLW-0630  
SHTP-01-06  
**P3** all other linear tables  
**P6** SHT(-C)-40  
SHT(-C)-50



\*\* See on display after 1 rotation by slope of 1,5