



igus® E-ChainSystems®




- ① Double stop dog for long unsupported length
- ② Large pins for long service life
- ③ Lateral glide surfaces for side-mounted operation
- ④ Available with extender crossbars for large hoses
- ⑤ Cable-friendly, smooth interior
- ⑥ Integrated strain relief possible
- ⑦ Serie 340 snap-open along inner radius can be combined with Serie 350 snap-open along outer radius, accessible from the top
- ⑧ Dirt-repellent, contoured exterior



Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222






igus® GmbH
51147 Cologne

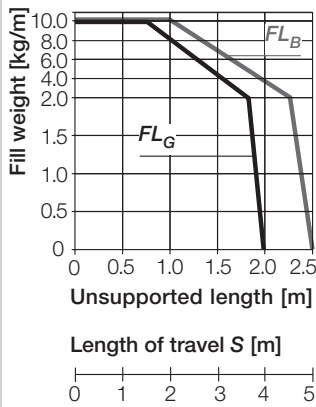

Unsupported length

FL_G = with straight upper run

FL_B = with permitted sag

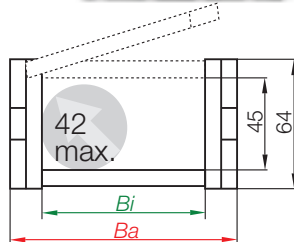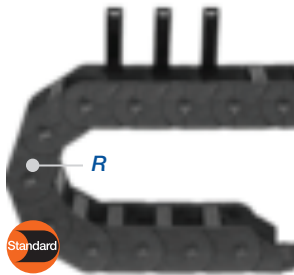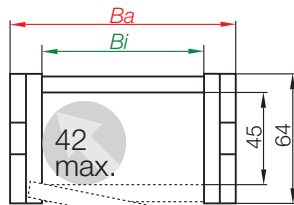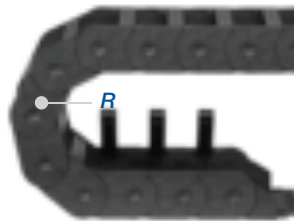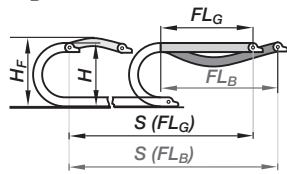

Series 340 - snap-open along inner radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
340.050.□.0	50	70	075 100 125
340.075.□.0	75	95	150 200 250
340.100.□.0	100	120	300
340.115.□.0	115	135	Radii for all widths!
340.125.□.0	125	145	
340.150.□.0	150	170	
340.175.□.0	175	195	
340.200.□.0	200	220	
340.225.□.0	225	245	
340.250.□.0	250	270	

Supplement Part No. with required radius. Example: 340.050.100.0
Bending radii listed above can be combined with every chain width!

Series 350 - snap-open along outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
350.050.□.0	50	70	075 100 115*
350.075.□.0	75	95	125 150 200
350.100.□.0	100	120	250 300
350.115.□.0	115	135	Radii for all widths!
350.125.□.0	125	145	
350.150.□.0	150	170	
350.175.□.0	175	195	
350.200.□.0	200	220	* not for Series 350.100
350.225.□.0	225	245	
350.250.□.0	250	270	

Supplement Part No. with required radius. Example: 350.150.100.0
Bending radii listed above can be combined with every chain width!

Part No. structure



350. 150.100.0

- Color black
- Bending radius
- Width
- Series



Order example 5,0 m complete E-Chain®

(indicate chain-lengths or number of links)

5,0 m (75 links) Series 350.150.100.0

+ 2 separators 311 assembled each 2nd link

+ 1 set mounting brackets + tiwrap plates 3150.34.PZB