


igus® E-ChainSystems®

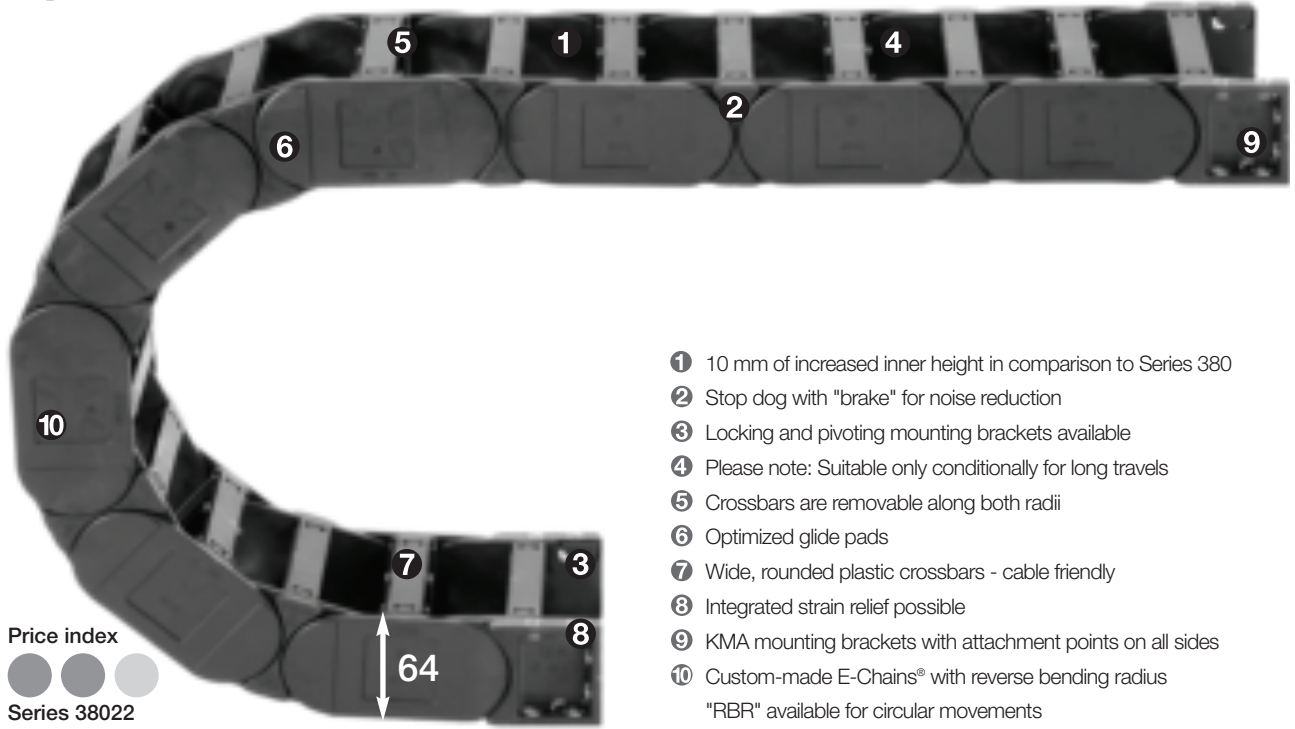


- ❶ 10 mm of increased inner height in comparison to Series 380
- ❷ Stop dog with "brake" for noise reduction
- ❸ Locking and pivoting mounting brackets available
- ❹ Please note: Suitable only conditionally for long travels
- ❺ Crossbars are removable along both radii
- ❻ Optimized glide pads
- ❼ Wide, rounded plastic crossbars - cable friendly
- ❽ Integrated strain relief possible
- ❾ KMA mounting brackets with attachment points on all sides
- ❿ Custom-made E-Chains® with reverse bending radius "RBR" available for circular movements

Price index


 Series 38022

Phone +49- (0) 22 03-96 49-800
 Fax +49- (0) 22 03-96 49-222


igus® GmbH
 51147 Cologne

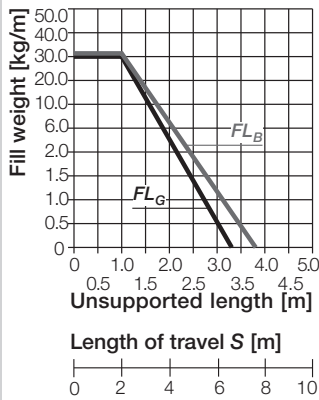

Unsupported length
 FL_G = with straight upper run
 FL_B = with permitted sag

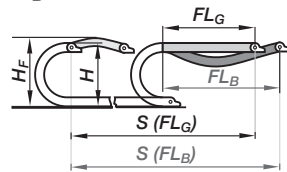

Serie 38022 - crossbars every link

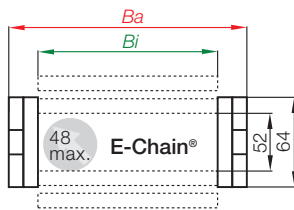

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
38022.05.	50	76	075 100 115
38022.06.	68	94	125 150 170
38022.07.	75	101	200 215 250
38022.087.	87	114	300 350
38022.10.	100	126	Radii for all widths!
38022.11.	108	134	
38022.112.	112	139	
38022.12.	125	151	
38022.137.	137	164	
38022.15.	150	176	
38022.162.	162	189	
38022.17.	168	194	
38022.18.	175	201	
38022.187.	187	214	
38022.20.	200	226	
38022.212.	212	239	
38022.23.	225	251	
38022.237.	237	264	
38022.25.	250	276	
38022.262.	262	289	
38022.28.	275	301	
38022.29.	287	314	
38022.30.	300	326	
38022.312.	312	339	
38022.325.	325	351	
38022.337.	337	364	
38022.350.	350	376	
38022.362.	362	389	
38022.375.	375	402	
38022.387.	387	414	
38022.400.	400	426	

Part No. structure

38022.400.300.0

- Color black
- Bending radius
- Width
- Series

Order example 5,0 m complete E-Chain®
 (indicate chain-lengths or number of links)

5,0 m (75 links) **Series 38022.400.300.0**
 + 2 separators **382213** assembled each 2nd link
 + 1 set KMA mounting brackets **38022.400.1.12.C**
 (with odd numbers of links and integrated C-profile)

Supplement Part No. with required radius. Example: **38022.400.300.0**
 Bending radii listed above can be combined with every chain width!