

Series R157 - hinged, snap-open on both sides of the inner radius

Part No.	B_i [mm]	B_a [mm]	R [mm]	Bending radii						Weight [kg/m]
157.040.□.0*	40	56	100	125	150	175	200	250	≈ 1,21	
157.050.□.0	50	66	100	125	150	175	200	250	≈ 1,30	
157.075.□.0	75	91	100	125	150	175	200	250	≈ 1,50	
157.088.□.0	88	104	100	125	150	175	200	250	≈ 1,57	
157.090.□.0**	88	104	100	125	150	175	200	250	≈ 1,63	
157.100.□.0	100	116	100	125	150	175	200	250	≈ 1,71	
157.125.□.0	125	141	100	125	150	175	200	250	≈ 1,92	
157.135.□.0	135	150	100	125	150	175	200	250	≈ 2,10	
157.150.□.0	150	166	100	125	150	175	200	250	≈ 2,13	
157.175.□.0	175	191	100	125	150	175	200	250	≈ 2,34	
157.200.□.0	200	216	100	125	150	175	200	250	≈ 2,55	



* Lid removable only, not hinged

** Same dimensions as 157.088 - less recent design, no hinged option

Supplement Part No. with required radius. Example: 157.100.100.0

0 = standard color, other colors ▶ page 1.39 · Pitch = 46 mm/link - Links/m = 22

Part No. structure

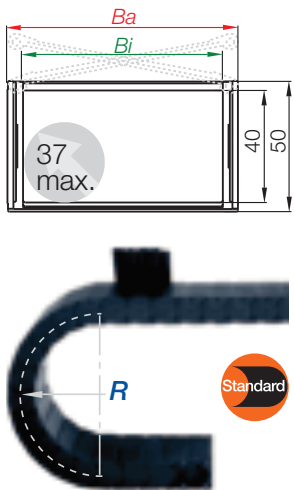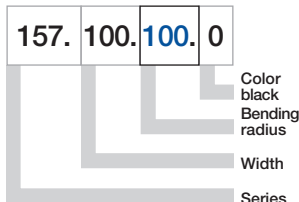

Series R158 - hinged, snap-open on both sides of the outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm]	Bending radii						Weight [kg/m]
158.040.□.0*	40	56	100	125	150	175	200	250	≈ 1,21	
158.050.□.0	50	66	100	125	150	175	200	250	≈ 1,30	
158.075.□.0	75	91	100	125	150	175	200	250	≈ 1,50	
158.088.□.0	88	104	100	125	150	175	200	250	≈ 1,57	
158.090.□.0**	88	104	100	125	150	175	200	250	≈ 1,63	
158.100.□.0	100	116	100	125	150	175	200	250	≈ 1,71	
158.125.□.0	125	141	100	125	150	175	200	250	≈ 1,92	
158.135.□.0	135	150	100	125	150	175	200	250	≈ 2,10	
158.150.□.0	150	166	100	125	150	175	200	250	≈ 2,13	
158.175.□.0	175	191	100	125	150	175	200	250	≈ 2,34	
158.200.□.0	200	216	100	125	150	175	200	250	≈ 2,55	

* Lid removable only, not hinged

** Same dimensions as 158.088 - less recent design, no hinged option

The size 125 is available upon request. Delivery time: approx. 8-10 weeks after receipt of order

Supplement Part No. with required radius. Example: 158.100.100.0

0 = standard color, other colors ▶ page 1.39 · Pitch = 46 mm/link - Links/m = 22

Part No. structure

