


Option 1: Vertical Separators

Vertical Separators are used if a vertical subdivision of the E-Chain® interior is required -


By standard Vertical Separators are assembled every other E-Chain® link

- **Standard** subdivision with Vertical Separator 1586.01
- **Asymmetrical Separator 1586.01.A** for side-mounted operations
- **Strain Relief Separator 1586.01.Z**, integrable in the mounting bracket, to position at any point - can be combined with Full-Width Shelf 221.X and Shelf 2210.X

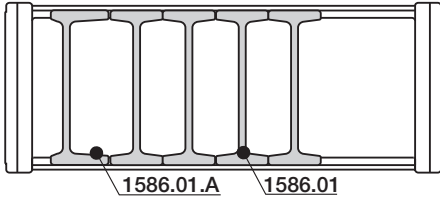


Vertical Separator

unassembled	1585.01
assembled	1586.01

 


Asymmetrical Separator

unassembled	1585.01.A
assembled	1586.01.A

 

Strain Relief Separator

unassembled	1585.01.Z
assembled	1586.01.Z

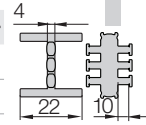


E2 E-Tubes Type R
Inner height: 40 mm

Option 2: Full-Width Shelves


For applications involving many thin cables with similar or identical diameters

- Vertical Separator, slotted 1586.02 for applications with Full-Width Shelf 221.X

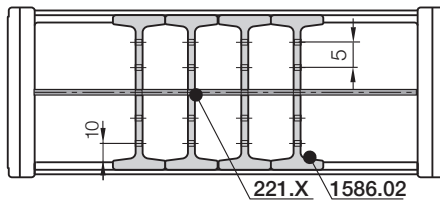

Vert. Separator, slotted


unassembled	1585.02
assembled	1586.02

 

Width X [mm]	Part No. unassembled	Part No. assembled
040	220.40	221.40
050	220.50	221.50
075	220.75	221.75
088	220.88	221.88
100	220.100	221.100

Width X [mm]	Part No. unassembled	Part No. assembled
125	220.125	221.125
135	220.135	221.135
150	220.150	221.150
175	220.175	221.175
200	220.200	221.200

 
Full-Width Shelf



Option 3: Shelves


For applications involving many cables with similar or identical diameters. Partial separation into individual chambers can be achieved and the entire width Bi-10 mm can be used

- Shelf 2210.X can be combined with Middle Plate 1586.03

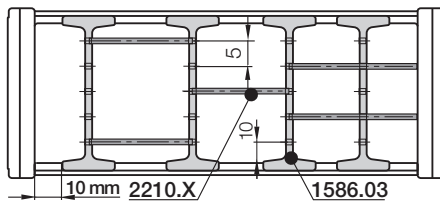

Middle Plate

unassembled	1585.03
assembled	1586.03

 

Width X [mm]	Part No. unassembled	Part No. assembled
018	2200.18	2210.18
023	2200.23	2210.23
028	2200.28	2210.28
033	2200.33	2210.33
038	2200.38	2210.38
043	2200.43	2210.43
048	2200.48	2210.48

Width X [mm]	Part No. unassembled	Part No. assembled
058	2200.58	2210.58
068	2200.68	2210.68
073	2200.73	2210.73
088	2200.88	2210.88
099	2200.99	2210.99
124	2200.124	2210.124
149	2200.149	2210.149

Shelf

