

**Slotted separator for E-Chains®**  
 unassembled **202**  
 assembled **212**

**Slotted separator 202 (E-Chains® only)**

is used when vertical and horizontal separation is required. Due to its slot, it allows basic vertical/horizontal shelving arrangements.

**Slotted separator for E-Tubes**  
 unassembled **24501**  
 assembled **24511**

**Slotted separator 24501 (E-Tubes only)**

is used when vertical and horizontal separation is required. Due to its slot, it allows basic vertical/horizontal shelving arrangements.

**Separator, wide foot\* for E-Chains®**  
 unassembled **201.28**  
 assembled **211.28**

**Separator, wide foot\* 201.28 (E-Chains® only)**

If a wide space between the separators has to be kept or separators have to be fixed in their position, e.g. for side-mounted applications. (\*for side-mounted applications)

**Side plate for E-Chains®**  
 unassembled **203**  
 assembled **213**

**Side plate 203 (E-Chains® only)**

Side plate for use with full-width shelf 220.X and slotted separator 202.

**Spacer\* for E-Chains®**  
 unassembled **205.09**  
 assembled **215.09**

**Spacer\* 205.09 (E-Chains® only)**

Separators can be fixed in position (only mountable along the inner radius of the fixed crossbar), (\*for side-mounted applications)

**Full-width shelf for E-Chains®/E-Tubes**  
 unassembled **220.X**  
 assembled **221.X**


**Full-width shelf 220.X (E-Chains® and E-Tubes)**

This option makes sense in applications with many thin cables with similar diameters. For a consequent subdivision. Full-width shelves can be arranged at 3 different heights (in 5 mm increments).

**Full-width shelves**

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
025	220.25	221.25	077	220.77	221.77	125	220.125	221.125
038	220.38	221.38	090	220.90	221.90			
057	220.57	221.57	103	220.103	221.103			



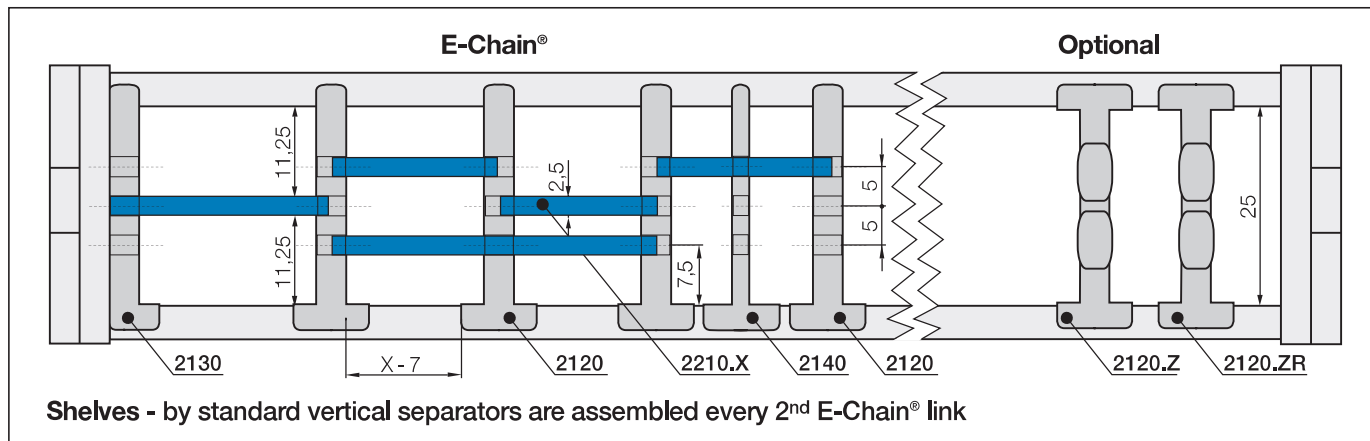

**Slotted middle plate  
E-Chains®**

unassembled	<b>2020</b>
assembled	<b>2120</b>

**Middle plate 2020 (E-Chains® only)**  
form the basic pattern of shelf 2200.X arranged at 3 different heights (in 5 mm increments)

**Slotted separator  
for E-Chains®**

unassembled	<b>2040</b>
assembled	<b>2140</b>

**Slotted separator 2040 (E-Chains® only)**  
For a very fine subdivision. No snap-in option for shelves, freely movable.

**Side plate  
for E-Chains®**

unassembled	<b>2030</b>
assembled	<b>2130</b>

**Side plate 2030 (E-Chains® only)**  
Side plate for use with middle plate 2020, slotted separator 2040 und shelf 2200.

**Shelf  
for E-Chains®**

unassembled	<b>2200.X</b>
assembled	<b>2210.X</b>

**Shelf 2200 (E-Chains® only)**  
For applications involving many cables with different diameters shelves can be arranged elevator-shifted. They can be arranged at 3 different heights (in 5 mm increments).

## Shelves

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
018	<b>2200.18</b>	<b>2210.18</b>	038	<b>2200.38</b>	<b>2210.38</b>	068	<b>2200.68</b>	<b>2210.68</b>
023	<b>2200.23</b>	<b>2210.23</b>	043	<b>2200.43</b>	<b>2210.43</b>	073	<b>2200.73</b>	<b>2210.73</b>
028	<b>2200.28</b>	<b>2210.28</b>	048	<b>2200.48</b>	<b>2210.48</b>	088	<b>2200.88</b>	<b>2210.88</b>
033	<b>2200.33</b>	<b>2210.33</b>	058	<b>2200.58</b>	<b>2210.58</b>	099	<b>2200.99</b>	<b>2210.99</b>

**Strain relief separator  
for E-Chains®**

unassembled	<b>2020.Z</b>
assembled	<b>2120.Z</b>

## Additional elements for interior separation

**Strain relief separator 2020.Z (E-Chains® only)**  
Can be integrated into the mounting bracket and can be placed there at any point. It combines strain relief and interior separation.

**Strain relief separator  
for E-Tubes**

unassembled	<b>2020.ZR</b>
assembled	<b>2120.ZR</b>

**Strain relief separator 2020.ZR (E-Tubes only)**  
Can be integrated into the mounting bracket and can be placed there at any point. It combines strain relief and interior separation.