

KMA = Polymer Metal Mounting Bracket


Option KMA, pivoting for E-Chains® Series 3400 and Series 3500

- Recommended for unsupported applications
- Bolted connection outside of chain cross-section
- Confined installation conditions
- Universal mountable with attachment capability on all sides
- Stackable

Moving end with bore

Series 3400 = 34001...1


Series 3500 = 34001...1

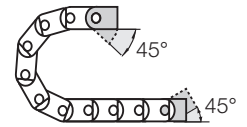


Series 3400 = 34001...2

Series 3400 = 34001...2

Fixed end with pin

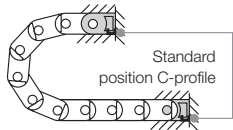

 The attachment variants arising automatically by the choice of the KMA mounting bracket



KMA = Polymer Metal Mounting Bracket


Option KMA, locking for E-Chains® Series 3400 and Series 3500

- Recommended for vertical hanging / standing applications
- Bolted connection outside of chain cross-section
- At very high speed and acceleration
- Universal mountable with attachment capability on all sides
- Stackable

Moving end with bore

Series 3400 = 34101...1


Series 3500 = 34101...1

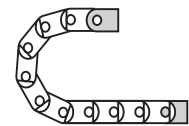

Series 3400 = 34101...2

Series 3500 = 34101...2

Fixed end with pin

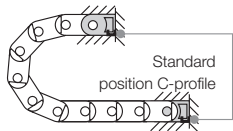


The attachment variants arising automatically by the choice of the KMA mounting bracket

Dimensions and order configurations

Part No. structure (pivoting)

34001.050.12.C A

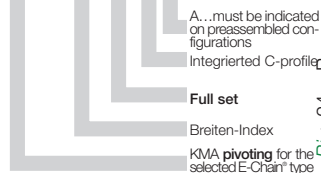

Full set, for both ends:

34001.050.12.C (with C-profile)

Single-part order:

34001.050.1.C (with C-profile)


Mounting bracket with bore

34001.050.2.C (with C-profile)

Mounting bracket with pin

Part No. structure (locking)

34101.050.12.C A

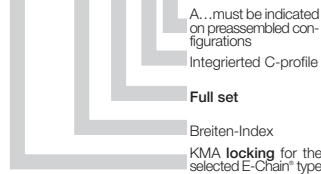

Full set, for both ends:

34101.050.12.C (with C-profile)

Single-part order:

34101.050.1.C (with C-profile)

Mounting bracket with bore


34101.050.2.C (with C-profile)

Mounting bracket with pin

3400 | 3500 = 34001...1 (pivoting)

3400 | 3500 = 34101...1 (locking)

Moving end

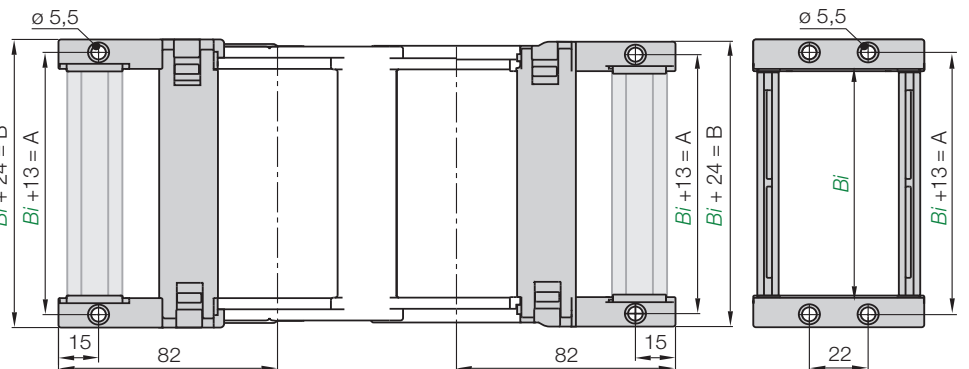

3400 | 3500 = 34001...2 (pivoting)

3400 | 3500 = 34101...2 (locking)

Fixed end

For E-Chain®	Part No. full set	Part No. full set	Dim. A [mm]	Dim B [mm]
Series 3400/3500	with C-profile	without C-profile		
3400/3500.050	...050.12.C	...050.12	63	74
3400/3500.075	...075.12.C	...075.12	88	99
3400/3500.100	...100.12.C	...100.12	113	124
3400/3500.115	...115.12.C	...115.12	128	139
3400/3500.125	...125.12.C	...125.12	138	149
3400/3500.150	...150.12.C	...150.12	163	174
3400/3500.175	...175.12.C	...175.12	188	199
3400/3500.200	...200.12.C	...200.12	213	224
3400/3500.225	...225.12.C	...225.12	238	249
3400/3500.250	...250.12.C	...250.12	263	274

● For **E-Chains®** please add the Part No. with the requested index

For the pivoting option e.g. 34001.050.12 or for the locking option e.g. 34101.050.12

For the **preassembled** mode please add the index **A** e.g. 34101.050.12 A